

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1713201022

Status:


Active

Overview:

Impel and Impel Plus Backplane Solutions

Description:

Impel 90 Ohm, 4 Pair Right-Angle Daughtercard, 1.90mm Pitch, Unguided, 12 Columns, 96 Circuits, Plated Through Hole Dimension 0.36mm

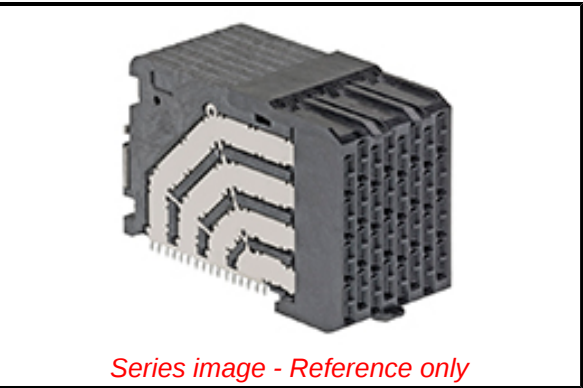

Documents:	
3D Model	Application Specification AS-171320-991-001 (PDF)
3D Model (PDF)	Application Specification AS-171320-992-001 (PDF)
Drawing (PDF)	Packaging Specification PK-78888-085-001 (PDF)
Product Specification PS-171320-999-001 (PDF)	Datasheet (PDF)
Application Specification 1713209994-AS-000 (PDF)	Symbol Footprint Data SYM-171320-1022-001 (PDF)
Application Specification AS-171320-990-001 (PDF)	RoHS Certificate of Compliance (PDF)

General	
Product Family	Backplane Connectors
Series	171320
Application	Coplanar, Daughtercard
Component Type	PCB Receptacle
Data Rate	40.0 Gbps
Overview	Impel and Impel Plus Backplane Solutions
Product Name	Impel
Taxonomy	Backplane Connectors
UPC	889056021579
Physical	
Circuits (Loaded)	96
Circuits (maximum)	96
Color - Resin	Black
Durability (mating cycles max)	200
First Mate / Last Break	No
Guide to Mating Part	No
Keying to Mating Part	None
Material - Metal	High Performance Alloy (HPA)
Material - Plating Mating	Gold
Material - Plating Termination	Tin
Material - Resin	High Temperature Thermoplastic
Net Weight	27.951/g
Number of Columns	12
Number of Pairs	4
Number of Rows	8
Orientation	Right Angle
PC Tail Length	1.30mm
PCB Locator	No
PCB Retention	None
PCB Thickness - Recommended	1.00mm
Packaging Type	Tray
Pitch - Mating Interface	1.90mm
Pitch - Termination Interface	1.90mm
Plating min - Mating	0.762µm
Temperature Range - Operating	-55° to +85°C
Electrical	
Current - Maximum per Contact	0.75A
Impedance	90Ω
Shield Type	Full Shield
Voltage - Maximum	29.9V AC (RMS)/DC

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2022)4187-DC (10 June 2022)	
Halogen-Free	
Status	
Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

171320 Series

Mates With

Impel Vertical Backplane Header

1713151207 , 1713151238 , 1713151218

Solder Process Data

Lead-freeProcess Capability N/A

Material Info

Reference - Drawing Numbers

Application Specification	1713209994-AS-000, AS-171320-990-001, AS-171320-991-001, AS-171320-992-001
Electrical Model Document	1713201218-000, 1713202061REVA-000
Packaging Specification	PK-78888-085-001
Product Specification	PS-171320-999-001
S-Parameter Model	1713201218-000, 1713202061-000
Sales Drawing	SD-171320-0001-001
Symbol/Footprint Data	SYM-171320-1022-001

This document was generated on 01/25/2023

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION