

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0015453620

Status:

Active

Overview:

C-Grid Connector Products

Description:

2.54mm Pitch C-Grid PCB Connector, Surface Mount, High Profile, Dual Row, Vertical, 20 Circuits

Documents:

3D Model	Application Specification 713080001-AS-000 (PDF)
Drawing (PDF)	Application Specification AS-71395-001-001 (PDF)
3D Model (PDF)	Packaging Specification PK-70873-0662-001 (PDF)
Product Specification PS-71395-001 (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification

CSA	LR19980
UL	E29179


General

Product Family	PCB Receptacles
Series	71395
Application	Board-to-Board, Signal
Component Type	PCB Receptacle
Overview	C-Grid Connector Products
Product Name	C-Grid
Taxonomy	PCB Headers and Receptacles
UPC	800755004267

Physical

Circuits (Loaded)	20
Circuits (maximum)	20
Color - Resin	Black
Durability (mating cycles max)	50
Flammability	94V-0
Glow-Wire Capable	No
Guide to Mating Part	No
Keying to Mating Part	None
Lock to Mating Part	No
Material - Metal	Phosphor Bronze
Material - Plating Mating	Gold
Material - Plating Termination	Tin
Material - Resin	High Temperature Thermoplastic
Net Weight	1.691/g
Number of Rows	2
Orientation	Vertical
PC Tail Length	1.47mm
PCB Locator	Yes
PCB Retention	Yes
PCB Thickness - Recommended	1.57mm
Packaging Type	Tray
Pitch - Mating Interface	2.54mm
Plating min - Mating	0.762µm
Plating min - Termination	1.905µm
Polarized to PCB	No
Surface Mount Compatible (SMC)	N/A
Temperature Range - Operating	-40° to +105°C
Termination Interface: Style	Surface Mount

Electrical

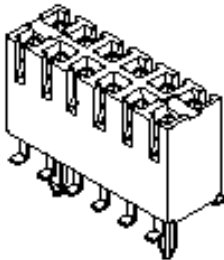

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -
D(2022)4187-DC (10
June 2022)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

[71395](#) Series

Mates With

C-Grid Vertical Header [70246](#) , [70567](#) . C-Grid Right-Angle Header [70247](#) , [74162](#) . C-Grid Vertical Breakaway Header [70280](#) , [71308](#) , [70287](#) . C-Grid Right-Angle Breakaway Header [71764](#) , [70216](#)

Current - Maximum per Contact	2.5A
Grounding to PCB	No
Voltage - Maximum	250V
Solder Process Data	
Lead-freeProcess Capability	REFLOW
Process Temperature max. C	260
Material Info	
Engineering Number	71395-0220
Reference - Drawing Numbers	
Application Specification	713080001-AS-000, AS-71395-001-001
Packaging Specification	PK-70873-0662-001
Product Specification	PS-71395-001
Sales Drawing	SDA-71395-0XXX-001

This document was generated on 02/04/2023

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION