

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:


0050160281

Status:

Active

Description:

15.88mm Pitch Phenolic Range Receptacle Housing, Black

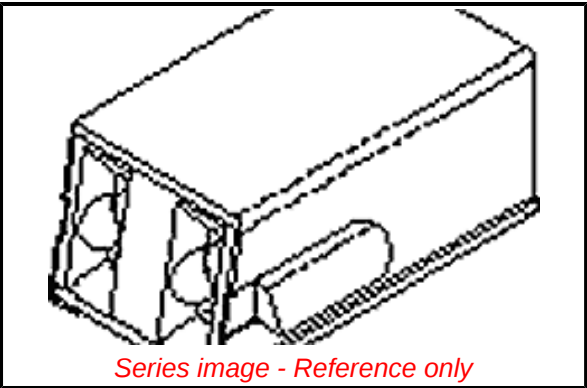

Documents:	
3D Model	3D Model (PDF)
Drawing (PDF)	RoHS Certificate of Compliance (PDF)
Agency Certification	
CSA	LR19980
General	
Product Family	Crimp Housings
Series	2481
Application	Signal, Wire-to-Board
Product Name	Range Receptacle
Taxonomy	Connector Housings
UPC	800753874992
Physical	
Circuits (maximum)	2
Color - Resin	Black
Flammability	94V-0
Gender	Receptacle
Glow-Wire Capable	No
Net Weight	20.500/g
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	15.88mm
Stackable	No
Temperature Range - Operating	0° to +150°C
Material Info	
Engineering Number	2481
Reference - Drawing Numbers	
Sales Drawing	SD-2481-X-001

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per -	
Halogen-Free	
Status	
Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

[2481](#) Series

Mates With

[2589](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION