

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0190190018

Status:


Active

Description:

.187 X .020 FEM.QD AVIK./REEL (AAZ-8137)

Documents:	
3D Model	Product Specification PS-19902-011-001 (PDF)
3D Model (PDF)	Product Specification PS-19902-014-001 (PDF)
Drawing (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR18689
UL	E79133
General	
Product Family	Quick Disconnects
Series	19019
Crimp Quality Equipment	Yes
Insulated	Partial
Taxonomy	Quick Disconnects
UPC	800753038035
Physical	
Flammability	94V-2
Insulation	Nylon (PA)
Net Weight	0.716/g
Solder Process Data	
Lead-freeProcess Capability	N/A
Material Info	
Engineering Number	AAZ-8137
Reference - Drawing Numbers	
Product Specification	PS-19902-011-001, PS-19902-014-001
Sales Drawing	SD-19019-001-001

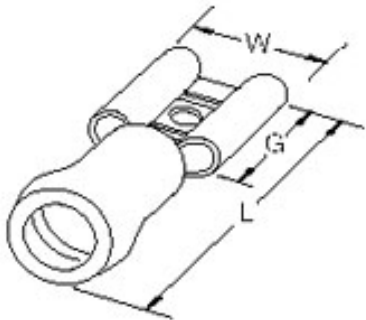

Series image - Reference only

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2022)4187-DC (10 June 2022)	
Halogen-Free	
Status	
Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

19019 Series

Application Tooling FAQ	
Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.	
Global	
Description	Product #
Mini-Mac Applicator	638810800

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION