

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0191150010

Status:

Active

Overview:

Solderless Terminals

Description:

Avikrimp Snap Spade Terminal for 18-22 AWG Wire

Documents:

3D Model

Product Specification PS-19902-011-001 (PDF)

3D Model (PDF)

RoHS Certificate of Compliance (PDF)

Drawing (PDF)

Agency Certification

CSA

LR18689

UL

E32244

General

Product Family

Ring and Spade Terminals

Series

19115

Crimp Quality Equipment

Yes

Overview

Solderless Terminals

Product Name

Avikrimp

Taxonomy

Ring and Spade Terminals

Type

Spade Snap

UPC

800753091894

Physical

Barrel Type

Closed

Flammability

94V-2

Insulation

Nylon (PA)

Material - Plating Mating

Tin

Net Weight

0.717/g

Packaging Type

Adhesive Tape on Reel

Plating min - Mating

4.064µm

Plating min - Termination

4.064µm

Stud Size

6 (M3.5)

Wire Insulation Diameter

3.60mm max.

Wire Size AWG

18, 20, 22

Solder Process Data

Lead-freeProcess Capability

N/A

Material Info

Engineering Number

AA-8704-06T


Reference - Drawing Numbers

Product Specification

PS-19902-011-001

Sales Drawing

SD-19115-001-001

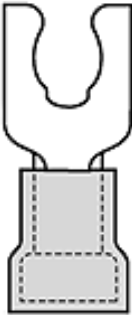

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

China RoHS

Compliant

REACH SVHC

Not Contained Per -

D(2022)4187-DC (10

June 2022)

Halogen-Free

Status

Low-Halogen

For more information, please visit

Contact US

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

19115 Series

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description

Product #

ATP Crimp Dies for the Tape Crimp Module and ATP-101 & 301 Press

192880023

FineAdjust Pneumatic Applicator for Ring and Spade Terminals, 18-22 AWG

638851300

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION