

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0190700104

Status:


Active

Overview:

Solderless Terminals

Description:

InsulKrimp Ring Tongue Terminal for 14-16 AWG Wire

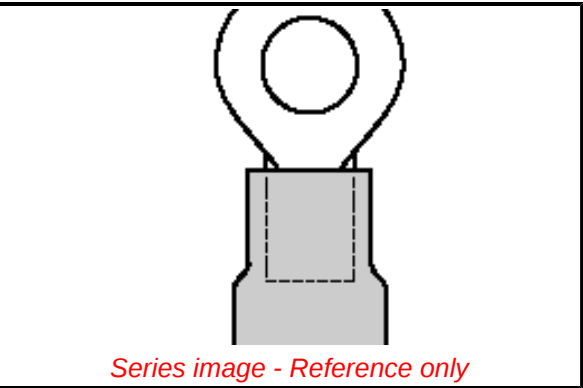

Documents:	
3D Model	Product Specification PS-19902-009-001 (PDF)
Drawing (PDF)	Product Specification PS-19902-011-001 (PDF)
3D Model (PDF)	RoHS Certificate of Compliance (PDF)
Agency Certification	
CSA	LR18689
UL	E32244
General	
Product Family	Ring and Spade Terminals
Series	19070
Crimp Quality Equipment	Yes
Overview	Solderless Terminals
Product Name	InsulKrimp
Taxonomy	Ring and Spade Terminals
Type	Ring
UPC	800753069534
Physical	
Barrel Type	Closed
Color - Resin	Natural
Flammability	94V-0
Insulation	PVC
Material - Plating Mating	Tin
Net Weight	0.876/g
Packaging Type	Adhesive Tape on Reel
Stud Size	10 (M5)
Wire Insulation Diameter	4.40mm max.
Wire Size AWG	14, 16
Wire Size mm²	1.30-2.00
Solder Process Data	
Lead-freeProcess Capability	N/A
Material Info	
Engineering Number	BB-239-10XT
Reference - Drawing Numbers	
Product Specification	PS-19902-009-001, PS-19902-011-001
Sales Drawing	SD-19070-008-001

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2022)4187-DC (10 June 2022)	
Halogen-Free Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

19070 Series

Application Tooling FAQ	
Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.	
Global	
Description	Product #
ATP Crimp Dies for the Tape Crimp Module and ATP-101 & 301 Press	192880123
Mini-Mac Applicator	638850400

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION