

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0190690094](#)
Status: **Active**
Overview: [Solderless Terminals](#)
Description: Krimptite Ring Tongue Terminal for 14-16 AWG Wire

Documents:	
3D Model	Product Specification PS-19902-011-001 (PDF)
3D Model (PDF)	Product Specification PS-19902-015-001 (PDF)
Drawing (PDF)	RoHS Certificate of Compliance (PDF)


Agency Certification	
CSA	LR18689
UL	E32244
General	
Product Family	Ring and Spade Terminals
Series	19069
Crimp Quality Equipment	Yes
Overview	Solderless Terminals
Product Name	Krimptite
Taxonomy	Ring and Spade Terminals
Type	Ring
UPC	800753067868

Physical	
Barrel Type	Closed
Insulation	None
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	1.045/g
Packaging Type	Adhesive Tape on Reel
Plating min - Mating	2.540µm
Plating min - Termination	2.540µm
Stud Size	3/8" (M9)
Termination Interface: Style	Crimp or Compression
Wire Size AWG	14, 16
Wire Size mm²	1.30-2.00

Solder Process Data	
Lead-freeProcess Capability	N/A

Material Info	
Engineering Number	BB-118-38T

Reference - Drawing Numbers	
Product Specification	PS-19902-011-001, PS-19902-015-001
Sales Drawing	SD-19069-013-001

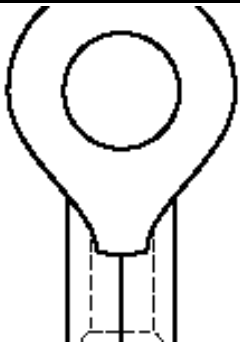

Series image - Reference only

EU ELV Not Relevant	
EU RoHS Compliant	China RoHS
REACH SVHC Not Contained Per - D(2022)4187-DC (10 June 2022)	
Halogen-Free Status Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[19069 Series](#)

Application Tooling | [FAQ](#)
Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global	
Description	Product #
Perishable Tooling	190270133
Spacers for tape product	
ATP Perishable	190270303
Tool Kit used in ATP	
Presses that Process	
Product on Tape	

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION