

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0191310022

Status:


Active

Overview:

Solderless Terminals

Description:

InsulKrimp Block Spade Tongue Terminal for 14 to 16 AWG Wire, Stud Size 6 (M3.5), Length 22.05mm

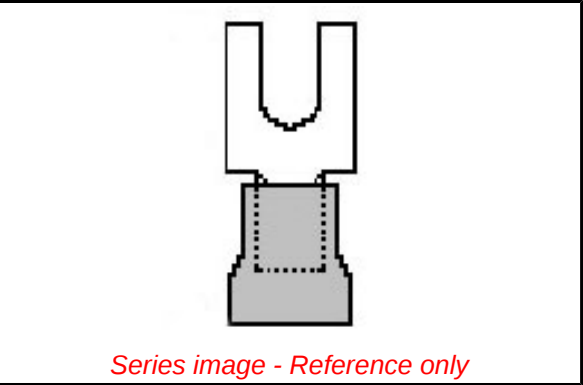

Documents:	
Drawing (PDF)	Product Specification PS-19902-015-001 (PDF)
Product Specification PS-19902-009-001 (PDF)	RoHS Certificate of Compliance (PDF)
Product Specification PS-19902-011-001 (PDF)	

Agency Certification	
CSA	LR18689
UL	E32244
General	
Product Family	Ring and Spade Terminals
Series	19131
Crimp Quality Equipment	Yes
Overview	Solderless Terminals
Product Name	InsulKrimp
Taxonomy	Ring and Spade Terminals
Type	Spade Block
UPC	800753101463
Physical	
Barrel Type	Closed
Color - Resin	Natural
Flammability	94V-0
Insulation	PVC
Material - Plating Mating	Tin
Net Weight	0.814/g
Packaging Type	Adhesive Tape on Reel
Plating min - Mating	2.540µm
Plating min - Termination	2.540µm
Stud Size	6 (M3.5)
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	4.40mm max.
Wire Size AWG	14, 16
Wire Size mm²	1.30-2.00
Material Info	
Engineering Number	BB-2471-06XT
Reference - Drawing Numbers	
Product Specification	PS-19902-009-001, PS-19902-011-001, PS-19902-015-001
Sales Drawing	191440028-000

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2022)4187-DC (10 June 2022)	
Halogen-Free	
Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

19131 Series

Application Tooling FAQ	
Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.	
Global	
Description	Product #
ATP Crimp Dies for the Tape Crimp Module and ATP-101 & 301 Press	192880123
Mini-Mac Applicator	638850400

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION