

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0191310019](#)
Status: **Active**
Overview: [Solderless Terminals](#)
Description: InsulKrimp Block Spade Tongue Terminal for 14 to 16 AWG Wire, Stud Size 6 (M3.5), Length 19.80mm

Documents:

Drawing (PDF)	Product Specification PS-19902-015-001 (PDF)
Product Specification PS-19902-009-001 (PDF)	RoHS Certificate of Compliance (PDF)
Product Specification PS-19902-011-001 (PDF)	

Agency Certification

CSA	LR18689
UL	E32244

General

Product Family	Ring and Spade Terminals
Series	19131
Crimp Quality Equipment	Yes
Overview	Solderless Terminals
Product Name	InsulKrimp
Taxonomy	Ring and Spade Terminals
Type	Spade Block
UPC	800753101425

Physical


Barrel Type	Closed
Color - Resin	Natural
Flammability	94V-0
Insulation	PVC
Material - Plating Mating	Tin
Net Weight	0.763/g
Packaging Type	Adhesive Tape on Reel
Plating min - Mating	2.540µm
Plating min - Termination	2.540µm
Stud Size	6 (M3.5)
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	4.40mm max.
Wire Size AWG	14, 16
Wire Size mm²	1.30-2.00

Material Info

Engineering Number	BB-2781-06XT
--------------------	--------------

Reference - Drawing Numbers

Product Specification	PS-19902-009-001, PS-19902-011-001, PS-19902-015-001
Sales Drawing	SD-19200-1001-001

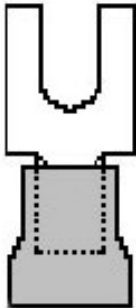

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2022)4187-DC (10
June 2022)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[19131](#) Series

Application Tooling | [FAQ](#)

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description	Product #
ATP Crimp Dies for the Tape Crimp Module and ATP-101 & 301 Press	192880123
Mini-Mac Applicator	638850400