

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0191150043

Status:

Active

Overview:

Solderless Terminals

Description:

Avikrimp Snap Spade Terminal for 10-12 AWG Wire

Documents:	
3D Model	Product Specification PS-19902-011-001 (PDF)
Drawing (PDF)	Product Specification PS-19902-015-001 (PDF)
3D Model (PDF)	RoHS Certificate of Compliance (PDF)


Agency Certification	
CSA	LR18689
UL	E32244
General	
Product Family	Ring and Spade Terminals
Series	19115
Crimp Quality Equipment	Yes
Overview	Solderless Terminals
Product Name	Avikrimp
Taxonomy	Ring and Spade Terminals
Type	Spade Snap
UPC	800753092402

Physical	
Barrel Type	Closed
Flammability	94V-2
Insulation	Nylon (PA)
Material - Plating Mating	Tin
Net Weight	1.865/g
Packaging Type	Adhesive Tape on Reel
Plating min - Mating	4.064µm
Plating min - Termination	4.064µm
Stud Size	5-6 (M3-3.5)
Wire Insulation Diameter	5.70mm max.
Wire Size AWG	10, 12

Solder Process Data	
Lead-freeProcess Capability	N/A

Material Info	
Engineering Number	C-8710-06T

Reference - Drawing Numbers	
Product Specification	PS-19902-011-001, PS-19902-015-001
Sales Drawing	191150041-000

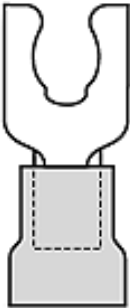

Series image - Reference only

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2022)4187-DC (10 June 2022)	
Halogen-Free	
Status	
Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

19115 Series

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global	
Description	Product #
ATP Crimp Dies for the Tape Crimp Module and ATP-101 & 301 Press	192880179
Mini-Mac Pneumatic Applicator for Industrial Terminals	638851500
6-26 AWG	

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION