

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0190540095

Status:

Active

Overview:

Solderless Terminals

Description:

InsulKrimp Ring Tongue Terminal for Heavy Duty 14-16 AWG Wire

Documents:

3D Model

Product Specification PS-19902-011-001 (PDF)

3D Model (PDF)

Product Specification PS-19902-015-001 (PDF)

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

Product Specification PS-19902-009-001 (PDF)

Agency Certification

CSA

LR18689

UL

E32244

General

Product Family

Ring and Spade Terminals

Series

19054

Comments

Heavy Duty

Crimp Quality Equipment

Yes

Overview

Solderless Terminals

Product Name

InsulKrimp

Taxonomy

Ring and Spade Terminals

Type

Ring

UPC

800753054745

Physical

Barrel Type

Closed

Color - Resin

Yellow

Flammability

94V-0

Insulation

PVC

Material - Plating Mating

Tin

Net Weight

2.147/g

Packaging Type

Adhesive Tape on Reel

Plating min - Mating

2.540µm

Plating min - Termination

2.540µm

Stud Size

10 (M5)

Termination Interface: Style

Crimp or Compression

Wire Insulation Diameter

6.40mm max.

Wire Size AWG

14, 16

Wire Size mm²

1.30-2.00

Solder Process Data

Lead-freeProcess Capability

N/A

Material Info

Engineering Number

B-228-10HDXT


Reference - Drawing Numbers

Product Specification

PS-19902-009-001, PS-19902-011-001, PS-19902-015-001

Sales Drawing

SD-19054-001-001

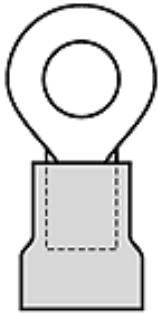

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

China RoHS

Compliant

REACH SVHC

Not Contained Per -

D(2022)4187-DC (10

June 2022)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit

Contact US

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

19054 Series

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global	
Description	Product #
ATP Crimp Dies for the Tape Crimp Module and ATP-101 & 301 Press	192880179
Mini-Mac Pneumatic Applicator for Industrial Terminals 6-26 AWG	638851500

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION