

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:0191420005

Status:Active

Description:SPADE INSULKRIMP (A-235-08X)

Documents:

- [Drawing \(PDF\)](#)
- [Product Specification PS-19902-009-001 \(PDF\)](#)
- [Product Specification PS-19902-011-001 \(PDF\)](#)
- [Product Specification PS-19902-013-001 \(PDF\)](#)
- [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSALR18689

ULE32244

General

Product FamilyRing and Spade Terminals

Series19142

Crimp Quality EquipmentYes

TaxonomyRing and Spade Terminals

UPC800753103429

Physical

Flammability94V-0

Net Weight0.827/g


Material Info

Engineering NumberA-235-08X

Reference - Drawing Numbers

Product SpecificationPS-19902-009-001, PS-19902-011-001, PS-19902-013-001

Sales Drawing191420003-000

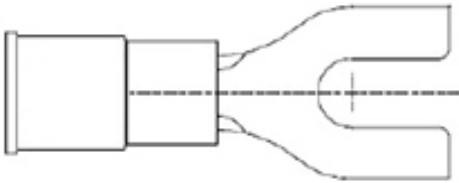

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -
D(2022)4187-DC (10
June 2022)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHSGreen Image

ELVNot Relevant

RoHS PhthalatesNot Contained

Search Parts in this Series

19142 Series

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description	Product #
PremiumGrade	640010100
Hand Crimp Tool for Avikrimp and Insulkrimp Terminals and Splices, 10-22 AWG and 6.0-0.5mm² (Rings, Spades, Hooks, Block Spades and Flanged Spades)	
Crimp Head for the AT-200 Pneumatic Hand Tool	640050100

ServiceGrade Hand 640160036
Crimp Tool for Field
Repair only, for
production use our
PremiumGrade Tool

This document was generated on 02/01/2023

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION