

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0191930250

Status:

Active

Overview:

VersaKrimp Terminals and Splices

Description:

VersaKrimp Ring Tongue Terminal for 6 AWG Wire, Stud Size M6, Mylar Tape Carrier

Documents:

Drawing (PDF)

Product Specification PS-19902-011-001 (PDF)

Product Specification PS-19902-011-001 (PDF)

Product Specification PS-19902-015-001 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification

CSA

LR18689

UL

E32244

General

Product Family

Ring and Spade Terminals

Series

19193

Crimp Quality Equipment

Yes

Overview

VersaKrimp Terminals and Splices

Product Name

VersaKrimp

Taxonomy

Ring and Spade Terminals

Type

Ring

UPC

800753040328

Physical

Barrel Type

Closed - Brazed

Insulation

None

Material - Plating Mating

Tin

Net Weight

4.600/g

Packaging Type

Adhesive Tape on Reel

Stud Size

1/4" (M6)

Wire Size AWG

6

Wire Size mm²

6.60-10.50

Solder Process Data

Lead-freeProcess Capability

N/A

Material Info

Engineering Number

E-360-14T


Reference - Drawing Numbers

Product Specification

PS-19902-011-001, PS-19902-015-001

Sales Drawing

SD-19193-032-001

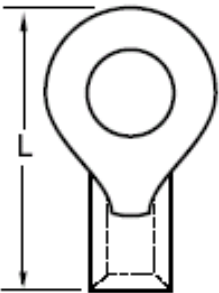

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -
D(2022)4187-DC (10
June 2022)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

19193 Series

Application Tooling | [FAQ](#)

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description	Product #
ATP Crimp Dies for the Tape Crimp Module and ATP-101 & 301 Press	190270145
Crimp Dies for 6 AWG Versakrimp Mylar Tape, use with the 640162000 Tape Crimp Module and 638017600 TM-4000 Crimp Press	190472010

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION