

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0191930139](#)
Status: **Active**
Overview: [VersaKrimp Terminals and Splices](#)
Description: VersaKrimp Ring Tongue Terminal for 10-12 AWG Wire, 3/8" (M9) Stud Size

Documents:
[Drawing \(PDF\)](#) [Product Specification PS-19902-015-001 \(PDF\)](#)
[Product Specification PS-19902-011-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR18689
UL E32244

General

Product Family Ring and Spade Terminals
Series [19193](#)
Comments Type I Non-insulated; Class 1 and 2
Crimp Quality Equipment Yes
Overview [VersaKrimp Terminals and Splices](#)
Product Name VersaKrimp
Taxonomy Ring and Spade Terminals
Type Ring
UPC 800753039421

Physical


Barrel Type Closed - Brazed
Insulation None
Material - Plating Mating Tin
Net Weight 1.955/g
Packaging Type Adhesive Tape on Reel
Plating min - Mating 2.540µm
Plating min - Termination 2.540µm
Stud Size 3/8" (M9)
Wire Size AWG 10, 12
Wire Size mm² 3.30-5.00

Material Info

Engineering Number C-340-38T

Reference - Drawing Numbers

Product Specification PS-19902-011-001, PS-19902-015-001
Sales Drawing SD-19193-026-001

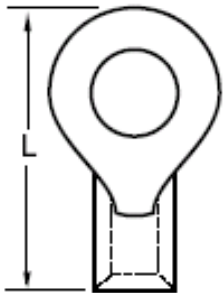

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

China RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2022)4187-DC (10
June 2022)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

[19193](#) Series

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description	Product #
Perishable Tooling	190270133
Spacers for tape product	
ATP Perishable	190270300
Tool Kit used in ATP	
Presses that Process Product on Tape	
Mini-Mac Applicator	638851000