

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0476591101](#)  
**Status:** **Active**  
**Overview:** [High Definition Multimedia Interface \(HDMI\)\\* Products](#)  
**Description:** HDMI Receptacle, Vertical, 8.50mm Mounted Height, Surface Mount, 0.38µm Gold (Au) Plating, with Cap, 19 Circuits, Tape and Reel, Lead-Free

**Documents:**

<a href="#">3D Model</a>	<a href="#">Product Specification 2086580001-000 (PDF)</a>
<a href="#">3D Model (PDF)</a>	<a href="#">Packaging Specification 476595100-000 (PDF)</a>
<a href="#">Drawing (PDF)</a>	<a href="#">RoHS Certificate of Compliance (PDF)</a>

**General**

Product Family	I/O Connectors
Series	<a href="#">47659</a>
Application	Wire-to-Board
Component Type	Receptacle
Overview	<a href="#">High Definition Multimedia Interface (HDMI)* Products</a>
Product Name	HDMI
Taxonomy	I/O Connectors
Type	A
UPC	193264442683

**Physical**


Circuits (Loaded)	19
Circuits (maximum)	19
Color - Resin	Black
Durability (mating cycles max)	10000
Gender	Female
Lock to Mating Part	Yes
Material - Metal	Brass
Material - Plating Mating	Gold
Material - Plating Termination	Gold
Material - Resin	Liquid Crystal Polymer
Net Weight	1.710/g
Number of Rows	2
Orientation	Vertical
PCB Locator	Yes
PCB Retention	Yes
Packaging Type	Embossed Tape on Reel
Panel Mount	Without Flange
Pitch - Mating Interface	0.50mm
Pitch - Termination Interface	0.50mm
Plating min - Mating	0.381µm
Plating min - Termination	0.051µm
Polarized to Mating Part	Yes
Polarized to PCB	Yes
Ports	1
Temperature Range - Operating	-20° to +85°C
Termination Interface: Style	Surface Mount

**Electrical**

Current - Maximum per Contact	0.5A
Shielded	Yes
Voltage - Maximum	40V DC

**Material Info**

**Reference - Drawing Numbers**

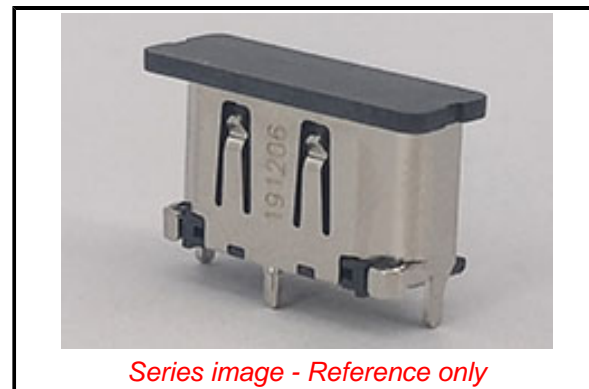

*Series image - Reference only*

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per -  
D(2022)4187-DC (10  
June 2022)

**Halogen-Free**

**Status**

**Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

[47659 Series](#)

Packaging Specification  
Product Specification  
Sales Drawing

476595100-000  
2086580001-000  
476591100-000

This document was generated on 12/05/2022

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**