

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0956225881

Status:

Active

Overview:

Magnetic and Modular Jacks/Plugs

Description:

Modular Jack, Right-Angle, Surface Mount, 8/8, Shielded, Reel

Documents:

3D Model

3D Model (PDF)

Drawing (PDF)

Product Specification PS-95622-001-001 (PDF)

Packaging Specification PK-95122-002-001 (PDF)

Datasheet (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification

UL

E107635

General

Product Family

Series

Comments

Component Type

Magnetic

Overview

Performance Category

Power over Ethernet (PoE)

Product Name

Taxonomy

UPC

Modular Jacks/Plugs

95622

Reflow Capable, External Shield

PCB Jack

No

Magnetic and Modular Jacks/Plugs

3

N/A

Modular Jack 8/8, RJ45

Modular Jacks and Plugs

884982486638

Physical

Boot Color

Color - Resin

Durability (mating cycles max)

Flammability

Inverted / Top Latch

Jack Height

Keying to Mating Part

Lightpipes/LEDs

Material - Metal

Material - Plating Mating

Material - Plating Termination

Material - Resin

Net Weight

Orientation

PCB Locator

PCB Retention

PCB Thickness - Recommended

Packaging Type

Pitch - Mating Interface

Pitch - Termination Interface

Plating min - Mating

Plating min - Termination

Port Configuration

Positions / Loaded Contacts

Surface Mount Compatible (SMC)

Temperature Range - Operating

Termination Interface: Style

Waterproof / Dustproof

Wire/Cable Type

N/A

Black

2500

94V-0

No

13.00mm

None

None

Copper Alloy

Gold over Palladium Nickel

Tin

High Temperature Thermoplastic

5.034/g

Right Angle (Side Entry)

No

Yes

1.57mm

Embossed Tape on Reel

1.02mm

1.27mm

0.051µm, 0.600µm

1.905µm

1x1

8/8


Yes

-40° to +85°C

Surface Mount

No

N/A

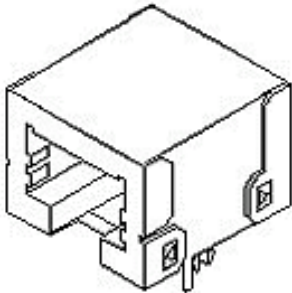

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -
D(2022)4187-DC (10
June 2022)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

Green Image

Not Relevant

Not Contained

Search Parts in this Series

95622 Series

Mates With

95043 Modular Plug, Short Body

Electrical

Current - Maximum per Contact	1.5A
Grounding to PCB	Yes
Grounding to Panel	None
Shielded	Yes
Voltage - Maximum	125V DC

Material Info

Reference - Drawing Numbers

Packaging Specification	PK-95122-002-001
Product Specification	PS-95622-001-001
Sales Drawing	SD-95622-012-001

This document was generated on 10/17/2022

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION