

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0760455001

Status:

Active

Overview:

SFP+ and SFP Interconnect Solutions

Description:

Small Form-factor Pluggable Plus (SFP+) Stacked 2-by-2 Multi-Port Connector with 4 Lightpipe Ports, EMI Metal Gasket, 80 Circuits, Tin (Sn) Tails

- Documents:
- 3D Model

Application Specification AS-76090-001-001 (PDF)
- 3D Model (PDF)

Packaging Specification PK-75714-001-001 (PDF)
- Drawing (PDF)

Test Summary TS-76092-999-001 (PDF)
- Product Specification PS-75310-001-001 (PDF)

RoHS Certificate of Compliance (PDF)
- Application Specification AS-75310-001-001 (PDF)

Agency Certification

CSA

LR19980

UL

E29179

General

Product Family

I/O Connectors

Series

76045

Application

Module-to-Board

Component Type

Receptacle

Electrical Model

Yes

Overview

SFP+ and SFP Interconnect Solutions

Product Name

SFP Plus, SFP+

Taxonomy

High-Speed Pluggable Connector

Type

N/A

UPC

800756878089

Physical

Boot Color

N/A

Circuits (Loaded)

80

Circuits (maximum)

80

Circuits Detail

80

Color - Resin

Black, Clear (Blue Tint)

Durability (mating cycles max)

100

Flammability

94V-0

Gender

Female

Keying to Mating Part

None

Lock to Mating Part

Yes

Material - Metal

High Performance Alloy (HPA)

Material - Plating Mating

Gold

Material - Plating Termination

Tin

Material - Resin

High Temperature Thermoplastic, Polycarbonate

Net Weight

50.387/g

Number of Rows

2

Orientation

Right Angle

PC Tail Length

2.07mm

PCB Locator

Yes

PCB Retention

Yes

PCB Thickness - Recommended

1.57mm

Packaging Type

Tray

Panel Mount

No

Pitch - Mating Interface

0.80mm

Pitch - Termination Interface


0.80mm

Plating min - Mating

0.762µm

Plating min - Termination

0.762µm

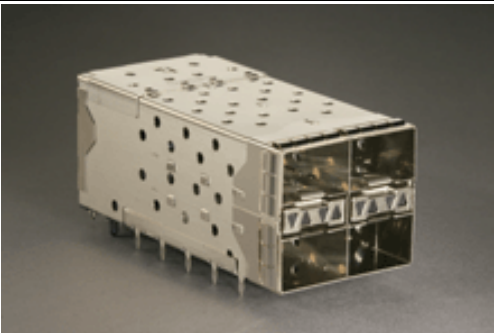

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -
D(2022)4187-DC (10
June 2022)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

76045 Series

Use With

759510999 SFP Dust Plug

Polarized to Mating Part	Yes
Polarized to PCB	Yes
Ports	4
Surface Mount Compatible (SMC)	No
Temperature Range - Operating	-40° to +85°C
Termination Interface: Style	Through Hole - Compliant Pin
Waterproof / Dustproof	No
Electrical	
Current - Maximum per Contact	0.5A
Grounding to Panel	None
Shield Type	EMI Gasket
Shielded	Yes
Voltage - Maximum	120V AC (RMS)/DC
Solder Process Data	
Lead-freeProcess Capability	N/A
Material Info	
Reference - Drawing Numbers	
Application Specification	AS-75310-001-001, AS-76090-001-001
Electrical Model Document	EE-76090-001-001
Packaging Specification	PK-75714-001-001
Product Specification	PS-75310-001-001
S-Parameter Model	SP-76090-001-001
Sales Drawing	SD-76045-001-001
Test Summary	TS-76092-999-001

This document was generated on 10/17/2022

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION