


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [2174802223](#)
Status: **Active**
Overview: [Off-the-Shelf Pre-Crimped Leads](#)
Description: Pre-Crimped Lead Mini-Fit Sr. Female-to-Mini-Fit Sr. Female, Gold (Au) Plating, 225.00mm Length, 8 AWG, Red

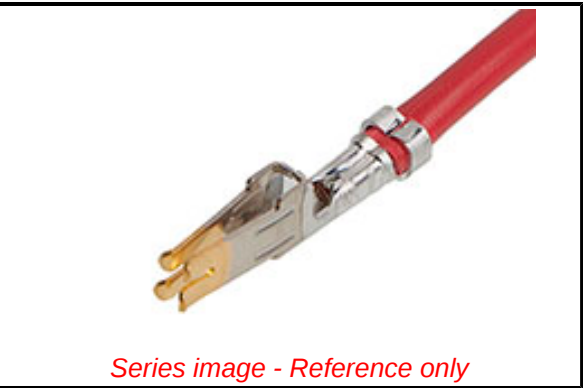

Documents:
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Datasheet \(PDF\)](#)

General
Product Family Cable Assemblies
Series [217480](#)
Application Power, Wire-to-Board, Wire-to-Wire
Assembly Configuration Pre-crimped Lead Only
Connector to Connector Mini-Fit Sr. Crimp Terminals
Overview [Off-the-Shelf Pre-Crimped Leads](#)
Product Name Mini-Fit Sr.
Taxonomy Power and Signal Cable Assembl
UPC 195842120891

Physical
Cable Length 225.00mm
Circuits (Loaded) 1
Color - Resin Red
Gender Female-Female
Lock to Mating Part Yes
Material - Metal High Performance Alloy (HPA)
Material - Plating Mating Gold
Material - Plating Termination Tin
Material - Resin PVC
Net Weight 27.276/g
Number of Rows 1
Packaging Type Bag
Plating min - Mating 0.762µm
Plating min - Termination 2.540µm
Single Ended No
Termination Interface: Style Crimp or Compression
Wire Insulation Diameter 6.60mm max.
Wire Size AWG 8
Wire/Cable Type UL 10669

Electrical
Current - Maximum per Contact 50.0A

Material Info

Reference - Drawing Numbers
Sales Drawing 2174801222-000

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -
D(2021)10043-DC (17
Jan 2022)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[217480 Series](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION