

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

2174832213

Status:


Active

Overview:

Off-the-Shelf Pre-Crimped Leads

Description:

Pre-Crimped Lead Mini-Fit Sr. Male-to-Pigtail, Gold (Au) Plating, 225.00mm Length, 10 AWG, Red

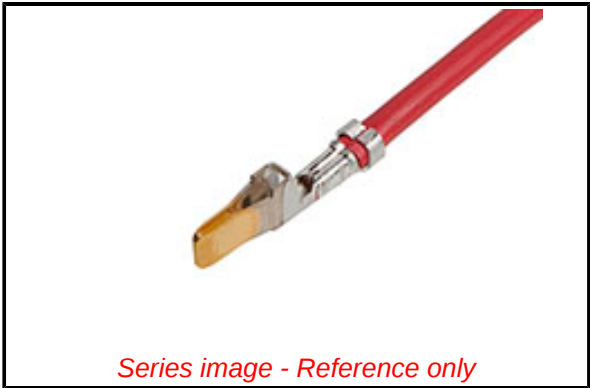

Documents:

[Drawing \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

[Datasheet \(PDF\)](#)

General

Product Family

Cable Assemblies

Series

217483

Application

Power, Wire-to-Wire

Assembly Configuration

Pre-crimped Lead Only

Connector to Connector

Mini-Fit Sr. Crimp Terminals

Overview

Off-the-Shelf Pre-Crimped Leads

Product Name

Mini-Fit Sr.

Taxonomy

Power and Signal Cable Assembl

UPC

195842122710

Physical

Cable Length

225.00mm

Circuits (Loaded)

1

Color - Resin

Red

Gender

Male-Pigtail

Lock to Mating Part

Yes

Material - Metal

High Performance Alloy (HPA)

Material - Plating Mating

Gold

Material - Plating Termination

Tin

Material - Resin

PVC

Net Weight

16.867/g

Number of Rows

1

Packaging Type

Bag

Plating min - Mating

0.762µm

Plating min - Termination

2.540µm

Single Ended

Yes

Termination Interface: Style

Crimp or Compression

Wire Insulation Diameter

6.60mm max.

Wire Size AWG

10

Wire/Cable Type

UL 10669

Electrical

Current - Maximum per Contact

33.0A

Material Info

Reference - Drawing Numbers

Sales Drawing

2174831212-000

EU ELV

Not Relevant

EU RoHS

China RoHS

Compliant

REACH SVHC

Not Contained Per - D(2022)4187-DC (10 June 2022)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

217483 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION