


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0151320400

Status: Active

Overview: Pico-Lock Connector System

Description: Pico-Lock-to-Pico-Lock Off-the-Shelf (OTS) Cable Assembly, 1.50mm Pitch, Single Row, 50.00mm Length, 4 Circuits, Black

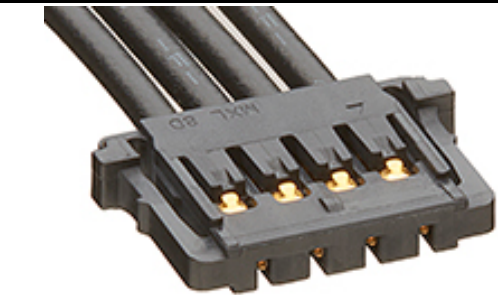

Series image - Reference only

Documents:

- 3D Model
- Drawing (PDF)
- 3D Model (PDF)
- Datasheet (PDF)
- RoHS Certificate of Compliance (PDF)

General

Product Family	Cable Assemblies
Series	15132
Application	Signal, Wire-to-Board
Assembly Configuration	Dual Ended Connectors
Connector to Connector	Pico-Lock-to-Pico-Lock
Overmolded	No
Overview	Pico-Lock Connector System
Product Name	Pico-Lock
Taxonomy	Power and Signal Cable Assembl
Type	Discrete Wire Assembly
UPC	191128284912

Physical

Cable Length	50.00mm
Circuits (Loaded)	4
Color - Resin	Black
Gender	Female-Female
Lock to Mating Part	Yes
Material - Metal	Copper Alloy
Material - Plating Mating	Gold
Material - Plating Termination	Tin
Material - Resin	High Temperature Thermoplastic
Net Weight	0.981/g
Number of Rows	1
Packaging Type	Bag
Pitch - Mating Interface	1.50mm
Single Ended	No
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	1.10mm
Wire Size AWG	24
Wire/Cable Type	UL 1061

Electrical

Current - Maximum per Contact	3.0A
Voltage - Maximum	150V

Material Info

Reference - Drawing Numbers

Sales Drawing	151320400-000
---------------	---------------

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -
D(2022)4187-DC (10
June 2022)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

15132 Series

Mates With

Pico-Lock Header [504050](#)