

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0150310433](#)
Status: **Active**
Overview: FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers
Description: 0.30mm Pitch Premo-Flex FPC Jumper with Notches, Same Side Contacts (Type A), 102.00mm Cable Length, Gold (Au) Plating, 33 Circuits

Documents:

[Drawing \(PDF\)](#) [Datasheet \(PDF\)](#)
[Product Specification 150310001-000 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

| | |
|-------------------------|---|
| Product Family | Cable |
| Series | 15031 |
| Crimp Quality Equipment | Yes |
| Overview | FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers |
| Product Name | Premo-Flex FFC Jumper |
| Taxonomy | Flexible Printed Circuit (FPC) |
| UPC | 195842786738 |

Physical

| | |
|-------------------------------|----------------------------|
| Cable Length | 102.00mm |
| Circuits (Loaded) | 33 |
| Circuits (maximum) | 33 |
| Contact Layout Type | A (same side) |
| Material - Plating Mating | Gold |
| Net Weight | 2.000/g |
| Packaging Type | Bag |
| Pitch - Mating Interface | 0.30mm |
| Temperature Range - Operating | -40° to +105°C |
| Wire Size AWG | N/A |
| Wire/Cable Type | Flexible Printed Circuitry |


Electrical

| | |
|-------------------------------|------|
| Current - Maximum per Contact | 0.2A |
| Voltage - Maximum | N/A |

Material Info

Reference - Drawing Numbers

| | |
|-----------------------|---------------|
| Product Specification | 150310001-000 |
| Sales Drawing | 150310001-000 |

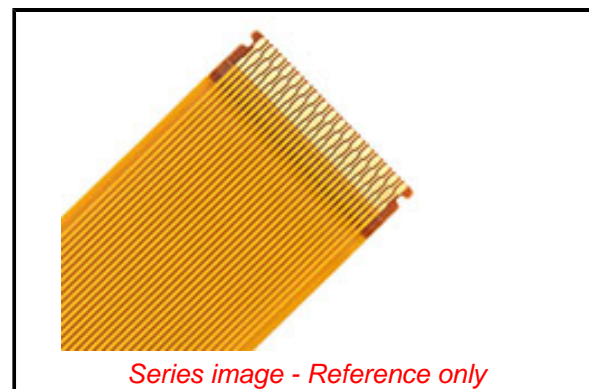

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2022)4187-DC (10
June 2022)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[15031 Series](#)

Mates With

Easy-On FPC Connector [5047543300](#)