

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0150310639

Status:


Active

Overview:

FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers

Description:

0.30mm Pitch Premo-Flex FPC Jumper with Notches, Same Side Contacts (Type A), 153.00mm Cable Length, Gold (Au) Plating, 39 Circuits

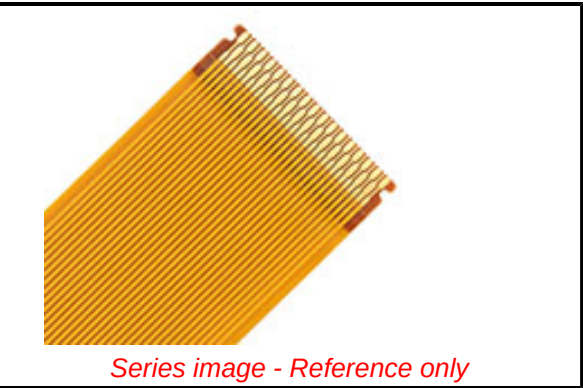

Documents:

Drawing (PDF)

Product Specification 150310001-000 (PDF)

Datasheet (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	Cable
Series	15031
Crimp Quality Equipment	Yes
Overview	FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers
Product Name	Premo-Flex FFC Jumper
Taxonomy	Flexible Printed Circuit (FPC)
UPC	195842788626
Physical	
Cable Length	152.00mm
Circuits (Loaded)	39
Circuits (maximum)	39
Contact Layout Type	A (same side)
Material - Plating Mating	Gold
Packaging Type	Bag
Pitch - Mating Interface	0.30mm
Temperature Range - Operating	-40° to +105°C
Wire Size AWG	N/A
Wire/Cable Type	Flexible Printed Circuitry
Electrical	
Current - Maximum per Contact	0.2A
Voltage - Maximum	N/A
Material Info	
Reference - Drawing Numbers	
Product Specification	150310001-000
Sales Drawing	150310001-000

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

Green Image

REACH SVHC

Not Contained Per - D(2022)4187-DC (10 June 2022)

Halogen-Free

Low-Halogen

Status

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

Green Image

Not Relevant

Not Contained

Search Parts in this Series

15031 Series

Mates With

Easy-On FPC Connector [5047543900](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION