

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0150310431](#)
Status: **Active**
Overview: [FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers](#)
Description: 0.30mm Pitch Premo-Flex FPC Jumper with Notches, Same Side Contacts (Type A), 102.00mm Cable Length, Gold (Au) Plating, 31 Circuits

Documents:

Drawing (PDF)	Datasheet (PDF)
Product Specification 150310001-000 (PDF)	RoHS Certificate of Compliance (PDF)

General

Product Family	Cable
Series	15031
Crimp Quality Equipment	Yes
Overview	FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers
Product Name	Premo-Flex FFC Jumper
Taxonomy	Flexible Printed Circuit (FPC)
UPC	195842786721

Physical

Cable Length	102.00mm
Circuits (Loaded)	31
Circuits (maximum)	31
Contact Layout Type	A (same side)
Material - Plating Mating	Gold
Net Weight	2.000/g
Packaging Type	Bag
Pitch - Mating Interface	0.30mm
Temperature Range - Operating	-40° to +105°C
Wire Size AWG	N/A
Wire/Cable Type	Flexible Printed Circuitry


Electrical

Current - Maximum per Contact	0.2A
Voltage - Maximum	N/A

Material Info

Reference - Drawing Numbers

Product Specification	150310001-000
Sales Drawing	150310001-000

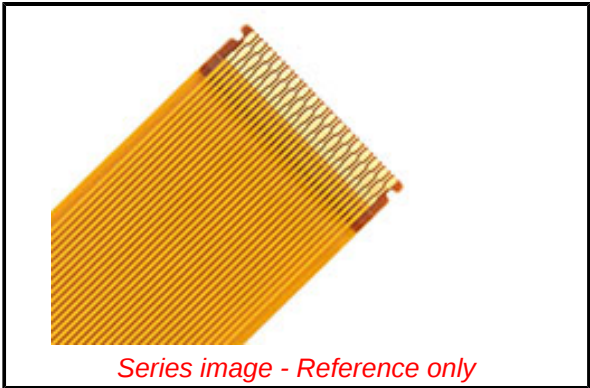

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -
D(2022)4187-DC (10
June 2022)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

[15031](#) Series

Mates With

Easy-On FPC Connector [5047543100](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION