

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0151350401](#)
Status: **Active**
Overview: CLIK-Mate Wire-to-Board Connectors
Description: CLIK-Mate-to-CLIK-Mate Off-the-Shelf (OTS) Cable Assembly, Single Row, 100.00mm Length, 4 Circuits, Beige

Documents:
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Datasheet \(PDF\)](#)


General
Product Family Cable Assemblies
Series [15135](#)
Application Signal, Wire-to-Board
Assembly Configuration Dual Ended Connectors
Connector to Connector CLIK-Mate-to-CLIK-Mate
Overmolded No
Overview [CLIK-Mate Wire-to-Board Connectors](#)
Product Name CLIK-Mate
Taxonomy Power and Signal Cable Assembl
Type Discrete Wire Assembly
UPC 191128156394

Physical
Cable Length 100.00mm
Circuits (Loaded) 4
Color - Resin Beige
Gender Male-Male
Lock to Mating Part Yes
Material - Metal Copper Alloy
Material - Plating Mating Tin
Material - Plating Termination Tin
Material - Resin PBT
Net Weight 2.037/g
Number of Rows 1
Packaging Type Bag
Pitch - Mating Interface 1.50mm
Plating min - Mating 0.406µm
Plating min - Termination 0.406µm
Single Ended No
Termination Interface: Style Crimp or Compression
Wire Insulation Diameter 1.10mm
Wire Size AWG 24
Wire/Cable Type UL 1061

Electrical
Current - Maximum per Contact 2.0A
Voltage - Maximum 100V AC (RMS)/DC

Material Info

Reference - Drawing Numbers
Sales Drawing 2012341675-000

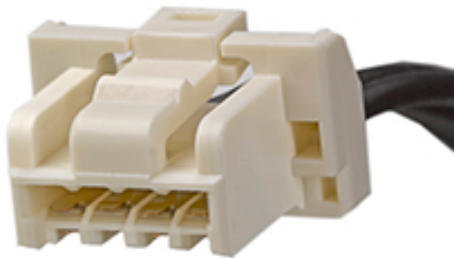

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -
D(2022)4187-DC (10
June 2022)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

[15135](#) Series

Mates With

Bottom-Entry Receptacle [503395](#) . Right Angle, Through Hole Receptacle [503175](#) . Right Angle, Surface Mount Receptacle [502585](#) . Vertical, Through Hole Receptacle [503159](#) . Vertical, Surface Mount Receptacle [502584](#)