

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0358431206

Status:

Active

Overview:

Automotive Bulb Sockets

Description:

PT Bulb Socket, Sealed, Single Housing Assembly, Type A, White

Documents:

3D Model


Drawing (PDF)

3D Model (PDF)

Packaging Specification PK-35843-001-001 (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	Other Sockets
Series	35843
Comments	A-Type
Component Type	Socket
Overview	Automotive Bulb Sockets
Product Name	Bulb Socket
Taxonomy	Sockets
UPC	756054269893
Physical	
Circuits (Loaded)	2
Circuits (maximum)	2
Color - Resin	White
Durability (mating cycles max)	30
Entry Angle	Vertical
Keying to Mating Part	None
Material - Resin	Nylon
Net Weight	10.114/g
PCB Locator	No
PCB Retention	N/A
Packaging Type	Bag
Pitch - Mating Interface	N/A
Temperature Range - Operating	-40° to +105°C
Termination Interface: Style	Through Hole
Electrical	
Current - Maximum per Contact	5.0A, 7.0A
Voltage - Maximum	12V
Material Info	
Reference - Drawing Numbers	
Packaging Specification	PK-35843-001-001
Sales Drawing	SD-35843-001-001

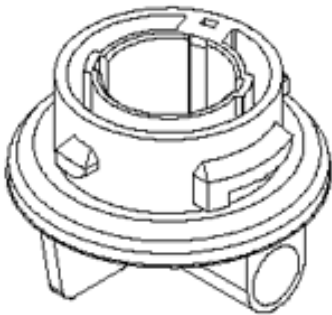

Series image - Reference only

EU ELV

Compliant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2022)4187-DC (10
June 2022)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China RoHS

Not Relevant

ELV

Compliant

RoHS Phthalates

Not Contained

Search Parts in this Series

35843 Series

Mates With

Lamp

Use With

Positive Terminal for PT Bulb Socket
354648000
Earth Terminal for PT Bulb
Socket 354658000
Positive Wire Seal
359030096
Earth Wire Seal 359030106

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION