


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0150200096
Status: Active
Overview: FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers
Description: 0.50mm Pitch Premo-Flex FFC Jumper, Opposite Side Contacts (Type D), 30.00mm Cable Length, Gold (Au) Plating, 10 Circuits

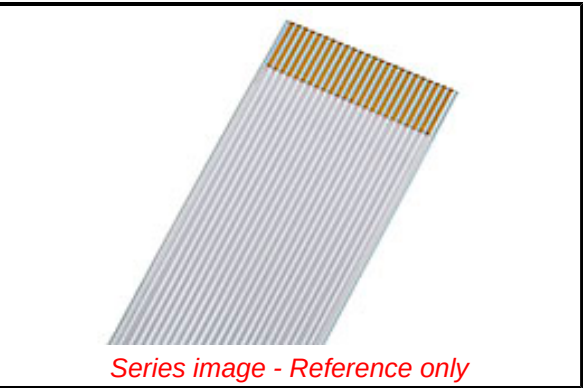

Series image - Reference only

Documents:

[Drawing \(PDF\)](#) [Datasheet \(PDF\)](#)
[Product Specification PS-15020-001-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family Cable
Series 15020
Comments Contacts on opposite sides, Type D
Crimp Quality Equipment Yes
Overview FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers
Product Name Premo-Flex FFC Jumper
Taxonomy Flexible Printed Circuit (FPC)
UPC 884982175587

Physical

Cable Length 30.00mm
Circuits (Loaded) 10
Contact Layout Type D (opposite side)
Material - Plating Mating Gold
Net Weight 0.112/g
Packaging Type Bag
Pitch - Mating Interface 0.50mm
Temperature Range - Operating -40° to +105°C
Wire Size AWG N/A
Wire/Cable Type Flat Flex Cable

Electrical

Current - Maximum per Contact 0.5A
Voltage - Maximum 60V AC

Material Info

Reference - Drawing Numbers

Product Specification PS-15020-001-001
Sales Drawing SD-15020-001-001

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -
ED/71/2019 (16 July
2019)

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

15020 Series

Mates With

Easy-On FFC/FPC Connector:

[5034801000](#) , [5051101092](#) , [527451097](#) ,
[527461071](#) , [5019511030](#) , [5019511050](#) ,
[525591052](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION