

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [2174811202](#)
Status: **Active**
Overview: [Off-the-Shelf Pre-Crimped Leads](#)
Description: Pre-Crimped Lead Mini-Fit Sr. Female-to-Pigtail, Gold (Au) Plating, 150.00mm Length, 12 AWG, Black

Documents:
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Datasheet \(PDF\)](#)


General
Product Family Cable Assemblies
Series [217481](#)
Application Power, Wire-to-Board, Wire-to-Wire
Assembly Configuration Pre-crimped Lead Only
Connector to Connector Mini-Fit Sr. Crimp Terminals
Overview [Off-the-Shelf Pre-Crimped Leads](#)
Product Name Mini-Fit Sr.
Taxonomy Power and Signal Cable Assembl
UPC 195842122222

Physical
Cable Length 150.00mm
Circuits (Loaded) 1
Color - Resin Black
Gender Female-Pigtail
Lock to Mating Part Yes
Material - Metal High Performance Alloy (HPA)
Material - Plating Mating Gold
Material - Plating Termination Tin
Material - Resin PVC
Net Weight 8.090/g
Number of Rows 1
Packaging Type Bag
Plating min - Mating 0.762µm
Plating min - Termination 2.540µm
Single Ended Yes
Termination Interface: Style Crimp or Compression
Wire Insulation Diameter 6.60mm max.
Wire Size AWG 12
Wire/Cable Type UL 10669

Electrical
Current - Maximum per Contact 23.0A

Material Info

Reference - Drawing Numbers
Sales Drawing 2174811202-000

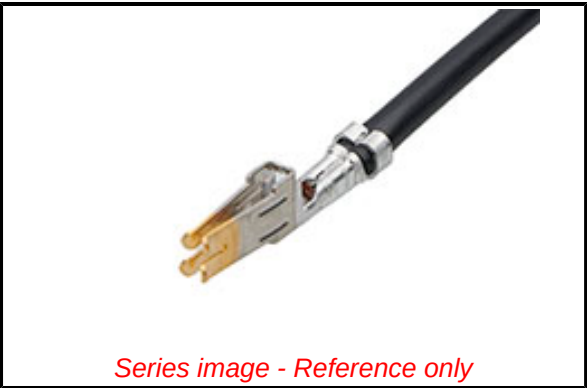

EU ELV
Not Relevant

EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2021)10043-DC (17 Jan 2022)	
Halogen-Free	
Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[217481](#) Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION