

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0150310609

Status:


Active

Overview:

FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers

Description:

0.30mm Pitch Premo-Flex FPC Jumper with Notches, Same Side Contacts (Type A), 153.00mm Cable Length, Gold (Au) Plating, 9 Circuits

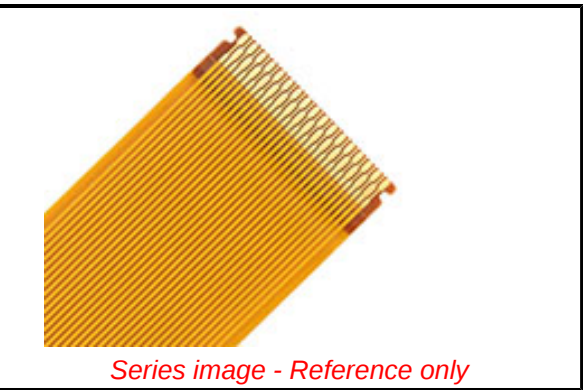

Documents:

[Drawing \(PDF\)](#)

[Product Specification 150310001-000 \(PDF\)](#)

[Datasheet \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

General	
Product Family	Cable
Series	15031
Crimp Quality Equipment	Yes
Overview	FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers
Product Name	Premo-Flex FFC Jumper
Taxonomy	Flexible Printed Circuit (FPC)
UPC	195842786813
Physical	
Cable Length	152.00mm
Circuits (Loaded)	9
Circuits (maximum)	9
Contact Layout Type	A (same side)
Material - Plating Mating	Gold
Net Weight	3.000/g
Packaging Type	Bag
Pitch - Mating Interface	0.30mm
Temperature Range - Operating	-40° to +105°C
Wire Size AWG	N/A
Wire/Cable Type	Flexible Printed Circuitry
Electrical	
Current - Maximum per Contact	0.2A
Voltage - Maximum	N/A
Material Info	
Reference - Drawing Numbers	
Product Specification	150310001-000
Sales Drawing	150310001-000

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -

D(2022)4187-DC (10

June 2022)

Halogen-Free

Status

Low-Halogen

For more information, please visit

Contact US

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

15031 Series

Mates With

Easy-On FPC Connector 5047540900

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION