

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0150140417

Status:


Active

Overview:

FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers

Description:

0.25mm Pitch Premo-Flex FPC Jumper, Same Side Contacts (Type A), 102.00mm Cable Length, Gold (Au) Plating, 17 Circuits

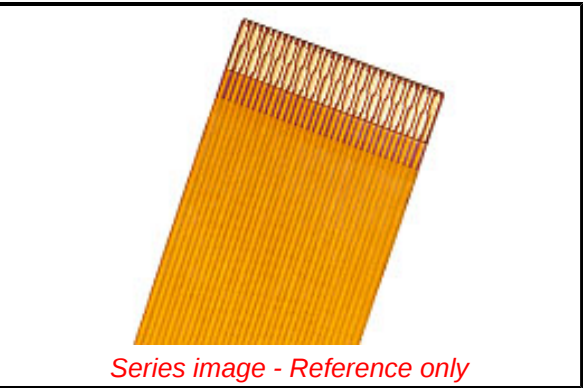

Series image - Reference only

Documents:

[Drawing \(PDF\)](#)

[Product Specification 1501400001-000 \(PDF\)](#)

[Datasheet \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

General	
Product Family	Cable
Series	15014
Crimp Quality Equipment	Yes
Overview	FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers
Product Name	Premo-Flex FFC Jumper
Taxonomy	Flexible Printed Circuit (FPC)
UPC	191130093298
Physical	
Cable Length	102.00mm
Circuits (Loaded)	17
Contact Layout Type	A (same side)
Material - Plating Mating	Gold
Net Weight	1.000/g
Packaging Type	Bag
Pitch - Mating Interface	0.25mm
Temperature Range - Operating	-40° to +105°C
Wire Size AWG	N/A
Wire/Cable Type	Flexible Printed Circuitry
Electrical	
Current - Maximum per Contact	0.2A
Voltage - Maximum	N/A
Material Info	
Reference - Drawing Numbers	
Product Specification	1501400001-000
Sales Drawing	150140001-000

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2022)4187-DC (10 June 2022)	
Halogen-Free	
Status	
Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

15014 Series

Mates With

Easy-On FPC Connector [5020781710](#) , [5020781762](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION