

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0150150245

Status:


Active

Overview:

FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers

Description:

0.30mm Pitch Premo-Flex Etched Copper Polyimide Jumper, Same Side Contacts (Type A), 51.00mm Cable Length, Gold (Au) Plating, 45 Circuits

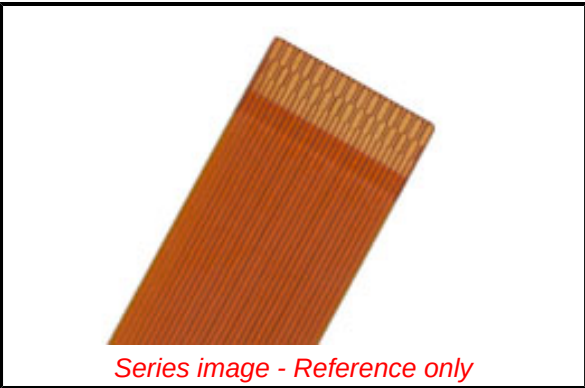

Documents:

[Drawing \(PDF\)](#)

[Product Specification PS-15015-001-001 \(PDF\)](#)

[Datasheet \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

General	
Product Family	Cable
Series	15015
Crimp Quality Equipment	Yes
Overview	FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers
Product Name	Premo-Flex FFC Jumper
Taxonomy	Flexible Printed Circuit (FPC)
UPC	884982822528
Physical	
Cable Length	51.00mm
Circuits (Loaded)	45
Contact Layout Type	A (same side)
Material - Plating Mating	Gold
Net Weight	1.000/g
Packaging Type	Bag
Pitch - Mating Interface	0.30mm
Temperature Range - Operating	-40° to +105°C
Wire Size AWG	N/A
Wire/Cable Type	Flexible Printed Circuitry
Electrical	
Current - Maximum per Contact	0.2A
Voltage - Maximum	50V AC/DC
Material Info	
Reference - Drawing Numbers	
Product Specification	PS-15015-001-001
Sales Drawing	SD-15015-001-001

EU ELV
Not Relevant

EU RoHS
Compliant
REACH SVHC
Not Contained Per -
D(2022)4187-DC (10
June 2022)
Halogen-Free
Status
Low-Halogen
For more information, please visit [Contact US](#)

China RoHS

China ROHS
ELV
RoHS Phthalates

Green Image
Not Relevant
Not Contained

Search Parts in this Series
15015 Series

Mates With
Easy-On FPC Connector [5025984593](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION