

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0150310239

Status:


Active

Overview:

FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers

Description:

0.30mm Pitch Premo-Flex FPC Jumper with Notches, Same Side Contacts (Type A), 51.00mm Cable Length, Gold (Au) Plating, 39 Circuits

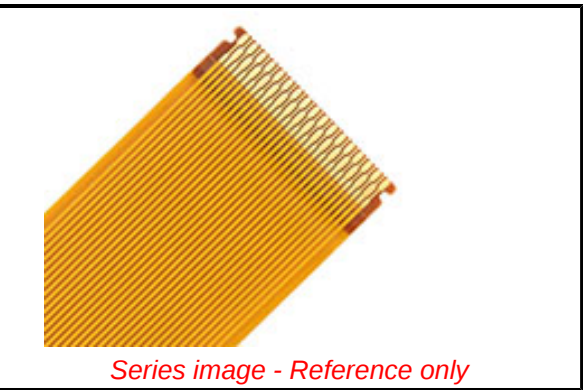

Documents:

[Drawing \(PDF\)](#)

[Product Specification 150310001-000 \(PDF\)](#)

[Datasheet \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

|                               |                                                           |
|-------------------------------|-----------------------------------------------------------|
| General                       |                                                           |
| Product Family                | Cable                                                     |
| Series                        | 15031                                                     |
| Crimp Quality Equipment       | Yes                                                       |
| Overview                      | FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers |
| Product Name                  | Premo-Flex FFC Jumper                                     |
| Taxonomy                      | Flexible Printed Circuit (FPC)                            |
| UPC                           | 195842786622                                              |
| Physical                      |                                                           |
| Cable Length                  | 51.00mm                                                   |
| Circuits (Loaded)             | 39                                                        |
| Circuits (maximum)            | 39                                                        |
| Contact Layout Type           | A (same side)                                             |
| Material - Plating Mating     | Gold                                                      |
| Net Weight                    | 1.000/g                                                   |
| Packaging Type                | Bag                                                       |
| Pitch - Mating Interface      | 0.30mm                                                    |
| Temperature Range - Operating | -40° to +105°C                                            |
| Wire Size AWG                 | N/A                                                       |
| Wire/Cable Type               | Flexible Printed Circuitry                                |
| Electrical                    |                                                           |
| Current - Maximum per Contact | 0.2A                                                      |
| Voltage - Maximum             | N/A                                                       |
| Material Info                 |                                                           |
| Reference - Drawing Numbers   |                                                           |
| Product Specification         | 150310001-000                                             |
| Sales Drawing                 | 150310001-000                                             |

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

Green Image

REACH SVHC

Not Contained Per - D(2022)4187-DC (10 June 2022)

Halogen-Free

Low-Halogen

Status

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

Green Image

Not Relevant

Not Contained

Search Parts in this Series

15031 Series

Mates With

Easy-On FPC Connector [5047543900](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION