

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0150310415

Status:

Active

Overview:

FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers

Description:

0.30mm Pitch Premo-Flex FPC Jumper with Notches, Same Side Contacts (Type A), 102.00mm Cable Length, Gold (Au) Plating, 15 Circuits

Documents:


Drawing (PDF)

Product Specification 150310001-000 (PDF)

Datasheet (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	Cable
Series	15031
Crimp Quality Equipment	Yes
Overview	FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers
Product Name	Premo-Flex FFC Jumper
Taxonomy	Flexible Printed Circuit (FPC)
UPC	195842786691
Physical	
Cable Length	102.00mm
Circuits (Loaded)	15
Circuits (maximum)	15
Contact Layout Type	A (same side)
Material - Plating Mating	Gold
Net Weight	2.000/g
Packaging Type	Bag
Pitch - Mating Interface	0.30mm
Temperature Range - Operating	-40° to +105°C
Wire Size AWG	N/A
Wire/Cable Type	Flexible Printed Circuitry
Electrical	
Current - Maximum per Contact	0.2A
Voltage - Maximum	N/A
Material Info	
Reference - Drawing Numbers	
Product Specification	150310001-000
Sales Drawing	150310001-000

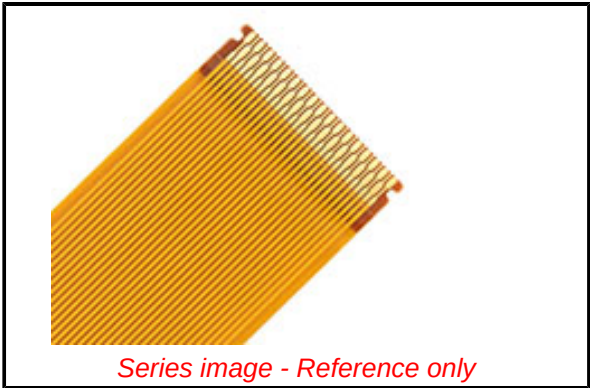

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per - D(2022)4187-DC (10 June 2022)

Halogen-Free

Status

Low-Halogen

For more information, please visit

Contact US

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

15031 Series

Mates With

Easy-On FPC Connector 5047541500

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION