

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0397000904](#)  
**Status:** **Active**  
**Overview:** Eurostyle Terminal Blocks  
**Description:** 5.00mm Pitch, Eurostyle Fixed-Mount Push-Button Terminal Block, Vertical, 10A, 22-14 AWG, Green, 4 Circuits

**Documents:**

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**General**

Product Family	Terminal Blocks
Series	<a href="#">39700</a>
Application	Wire-to-Board
Component Type	Push-Button
Overview	<a href="#">Eurostyle Terminal Blocks</a>
Product Name	ESE, Eurostyle Fixed Mount
Taxonomy	Terminal Blocks and Barrier St
Type	Euro Block
UPC	78172542642

**Physical**

Circuits (Loaded)	4
Circuits (maximum)	4
Color - Resin	Green
Entry Angle	Vertical
Lock to Mating Part	No
Material - Plating Termination	Tin
Material - Resin	Nylon
Net Weight	6.000/g
Number of Rows	1
Orientation	Vertical
Panel Mount	Yes
Pitch - Mating Interface	5.00mm
Polarized to Mating Part	No
Stackable	No
Temperature Range - Operating	-40° to +105°C
Wire Size AWG	14, 16, 18, 20, 22

**Electrical**


Current - Maximum per Contact	10.0A
Voltage - Maximum	300V

**Material Info**

Engineering Number	M851-01-1-04-3
--------------------	----------------

**Reference - Drawing Numbers**

Sales Drawing	SD-39700-010-001
---------------	------------------

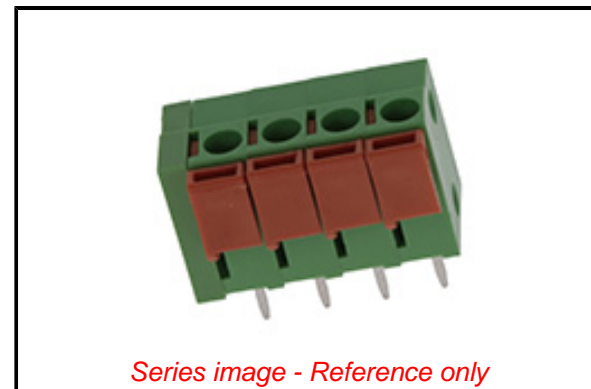

*Series image - Reference only*

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per -  
D(2022)4187-DC (10  
June 2022)

**Halogen-Free**

**Status**

**Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

[39700 Series](#)