

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0192040008

Status:

Active

Overview:

Splices

Description:

Avikrimp 4 Way Splice for 18-22 AWG Wire

Documents:

Drawing (PDF)


Product Specification PS-19902-009-001 (PDF)

Product Specification PS-19902-011-001 (PDF)

Product Specification PS-19902-013-001 (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	Splices
Series	19204
Comments	4 Way Connector
Crimp Quality Equipment	Yes
Overview	Splices
Product Name	4 Way, Avikrimp
Taxonomy	Splices
UPC	800753051607
Physical	
Barrel Type	Closed
Color - Resin	Red
Insulation	Nylon (PA)
Material - Metal	Copper
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Material - Resin	Nylon
Net Weight	10.284/g
Packaging Type	Bag
Temperature Range - Operating	-55° to +105°C
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	3.56mm max.
Wire Size AWG	18, 20, 22
Wire Size mm²	0.35-0.80
Electrical	
Voltage - Maximum	600V
Material Info	
Engineering Number	A-5XC
Reference - Drawing Numbers	
Product Specification	PS-19902-009-001, PS-19902-011-001, PS-19902-013-001
Sales Drawing	SD-19204-002-001

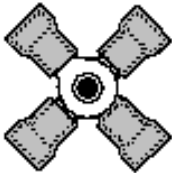

Series image - Reference only

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2021)4569-DC (8 July 2021)	
Halogen-Free	
Status	
Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

19204 Series

Application Tooling | [FAQ](#)

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global	
Description	Product #
PremiumGrade Hand Crimp Tool for Avikrimp and Insulkrimp Terminals and Splices, 10-22 AWG and 6.0-0.5mm² (Rings, Spades, Hooks, Block Spades and Flanged Spades) Crimp Head for the AT-200 Pneumatic Hand Tool	640010100
	640050100

ServiceGrade Hand 640160036
Crimp Tool for Field
Repair only, for
production use our
PremiumGrade Tool

This document was generated on 02/01/2023

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION