

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0982761001

Status:

Active

Overview:

NSCC - New Standard Casing Contact

Description:

3.33mm / 6.00mm Pitch Hybrid Male Inline Housing, Dual Row, 16 Circuits, Black

Documents:

3D Model

Packaging Specification PK-98276-001-001 (PDF)

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

Application Specification AS-98276-001-001 (PDF)

General

Product Family

Series

Application

Comments

Crimp Housings

98276

Power, Wire-to-Wire

For current designation please refer to FCI Sicma terminal specification for 1.50 and 2.80mm terminals.

Overview

Product Name

Taxonomy

UPC

NSCC - New Standard Casing Contact

NSCC

Connector Housings

756054713419

Physical

Circuits (maximum)

Circuits Detail

Color - Resin

Gender

Glow-Wire Capable

Lock to Mating Part

Material - Resin

Net Weight

Number of Rows

Packaging Type

Panel Mount

Pitch - Mating Interface

Polarized to Mating Part

Ports

Stackable

Temperature Range - Operating

16

4x2.8mm 12x1.5mm male terminals

Black, Natural

Plug

No

Yes

Polyester, Polyester Alloy

12.361/g

2

Bag

No

3.33mm, 6.00mm

Yes

1

No

-40° to +85°C

Solder Process Data

Lead-freeProcess Capability

N/A

Material Info

Reference - Drawing Numbers

Application Specification


Packaging Specification

Sales Drawing

AS-98276-001-001

PK-98276-001-001

SD-98276-001-001

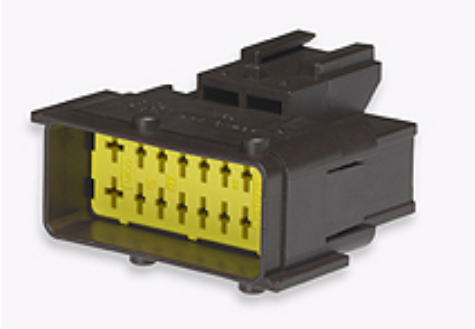

Series image - Reference only

EU ELV

Compliant

EU RoHS

Compliant

REACH SVHC

Not Contained Per - D(2022)4187-DC (10 June 2022)

Halogen-Free

Status

Not Relevant

For more information, please visit [Contact US](#)

China RoHS

Not Relevant

ELV

Compliant

RoHS Phthalates

Not Contained

Search Parts in this Series

98276 Series

Mates With

982731001

Use With

1.5 and 2.8mm FCI Sicma Male Terminals

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION