

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0196020006

Status:

Active

Overview:

Standard Quick-Disconnect Terminals

Description:

Avikrimp Fully Insulated Piggyback Quick Disconnect, Tab 6.35 x 0.81mm, 10-12 AWG, Yellow Insulator, Loose

Documents:

3D Model

Drawing (PDF)

3D Model (PDF)

Product Specification PS-19902-013-001 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification

UL

E79133

General

Product Family

Series

Crimp Quality Equipment

Insulated

Overview

Product Name

Taxonomy

Type

UPC

Quick Disconnects

19602

Yes

Fully

Standard Quick-Disconnect Terminals

Avikrimp

Quick Disconnects

Quick Disconnect

822350974073

Physical

Barrel Type

Color - Resin

Flammability

Gender

Glow-Wire Capable

Insulation

Lock to Mating Part

Material - Metal

Material - Plating Mating

Material - Plating Termination

Net Weight

Orientation

Packaging Type

Polarized to Mating Part

Tab Thickness

Tab Width

Wire Insulation Diameter

Wire Size AWG

Wire Size mm²

Closed

Yellow

94V-2

Female

No

Nylon (PA)

No

Brass

Tin

Tin

2.182/g

Straight

Bag

No

0.81mm

6.35mm

3.53mm max.

10, 12

1.30-2.00

Electrical

Voltage - Maximum

600V

Material Info

Engineering Number

C-5319


Reference - Drawing Numbers

Product Specification

Sales Drawing

PS-19902-013-001

SD-19602-001-001

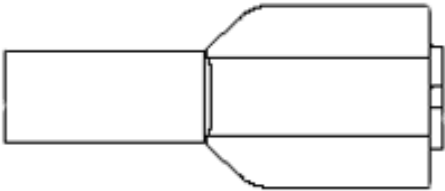

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

China RoHS

Compliant

REACH SVHC

Not Contained Per -

ED/30/2017 (7 July

2017)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

19602 Series

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description

Product #

Hand Crimp Tool

640016400

This document was generated on 01/31/2023

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION