

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0192040013

Status:

Active

Overview:

Splices

Description:

InsulKrimp 4 Way Splice for 14-16 AWG Wire

Documents:

Drawing (PDF)

Product Specification PS-19902-009-001 (PDF)

Product Specification PS-19902-011-001 (PDF)

Product Specification PS-19902-013-001 (PDF)

RoHS Certificate of Compliance (PDF)

General

Product Family

Series

Comments

Crimp Quality Equipment

Overview

Product Name

Taxonomy

UPC

Splices

19204

4 Way Connector

Yes

Splices

4 Way, InsulKrimp

Splices

800753051638

Physical

Barrel Type

Color - Resin

Insulation

Material - Metal

Material - Plating Mating

Material - Plating Termination

Material - Resin

Net Weight

Packaging Type

Plating min - Mating

Plating min - Termination

Temperature Range - Operating

Wire Insulation Diameter

Wire Size AWG

Wire Size mm²

Closed

Blue

PVC

Copper

Tin

Tin

PVC

4.372/g

Bag

2.540µm

2.540µm

-40° to +105°C

4.45mm max.

14, 16

1.30-2.00

Electrical

Voltage - Maximum

600V

Solder Process Data

Lead-freeProcess Capability

N/A

Material Info

Engineering Number

B-2XCX


Reference - Drawing Numbers

Product Specification

Sales Drawing

PS-19902-009-001, PS-19902-011-001, PS-19902-013-001

SD-19204-002-001

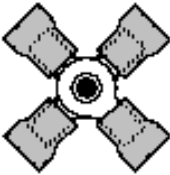

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

China RoHS

Compliant

REACH SVHC

Not Contained Per - D(2021)4569-DC (8 July 2021)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

19204 Series

Application Tooling | [FAQ](#)

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global	
Description	Product #
PremiumGrade Hand Crimp Tool for Avikrimp and Insulkrimp Terminals and Splices, 10-22 AWG and 6.0-0.5mm² (Rings, Spades, Hooks, Block Spades and Flanged Spades)	640010100
PremiumGrade Hand Crimp Tool for Insulkrimp Terminals and Splices, 10-22	640010300

AWG (Rings,
Spades, Hooks,
Block Spades and
Flanged Spades)
Crimp Head for the 640050100
AT-200 Pneumatic
Hand Tool
Crimp Head for the 640050300
AT-200 Pneumatic
Hand Tool
ServiceGrade Hand 640160036
Crimp Tool for Field
Repair only, for
production use our
PremiumGrade Tool

This document was generated on 02/01/2023
PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION