

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0190670052](#)
Status: **Active**
Overview: Solderless Terminals
Description: NylaKrimp Funnel Entry Ring Tongue Terminal for 6 AWG Wire, Stud Size 3/8" (M9)

Documents:

| | |
|--|--|
| 3D Model | Product Specification PS-19902-013-001 (PDF) |
| Drawing (PDF) | Product Specification PS-19902-016-001 (PDF) |
| 3D Model (PDF) | RoHS Certificate of Compliance (PDF) |
| Product Specification PS-19902-011-001 (PDF) | |

Agency Certification

| | |
|-----|---------|
| CSA | LR18689 |
| UL | E32244 |

General

| | |
|-------------------------|--------------------------------------|
| Product Family | Ring and Spade Terminals |
| Series | 19067 |
| Crimp Quality Equipment | Yes |
| Overview | Solderless Terminals |
| Product Name | NylaKrimp |
| Taxonomy | Ring and Spade Terminals |
| Type | Ring |
| UPC | 800753066021 |

Physical


| | |
|------------------------------|----------------------|
| Barrel Type | Closed - Brazed |
| Flammability | 94V-2 |
| Insulation | Nylon (PA) |
| Material - Plating Mating | Tin |
| Net Weight | 5.931/g |
| Packaging Type | Bag |
| Plating min - Mating | 2.540µm |
| Plating min - Termination | 2.540µm |
| Stud Size | 3/8" (M9) |
| Termination Interface: Style | Crimp or Compression |
| Wire Insulation Diameter | 10.87mm max. |
| Wire Size AWG | 6 |

Material Info

| | |
|--------------------|----------|
| Engineering Number | E-957-38 |
|--------------------|----------|

Reference - Drawing Numbers

| | |
|-----------------------|--|
| Product Specification | PS-19902-011-001, PS-19902-013-001, PS-19902-016-001 |
| Sales Drawing | SD-19067-013-001 |

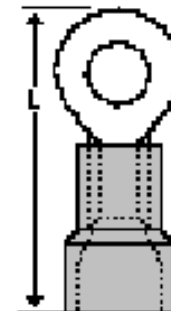

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per - D(2022)4187-DC (10 June 2022)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[19067 Series](#)

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

| Description | Product # |
|---|---------------------------|
| Manual Putt Pump Hydraulic System, Die set required | 192860117 |
| Die Set (large) for the HHLS Hydraulic Crimper | 192890004 |
| Hydraulic Dieless Crimping Tool | 638161700 |
| PremiumGrade Hand Crimp Tool for 2-8 AWG Terminals | 640013900 |
| Crimp Tool Kit for 6 AWG Insulated Ring Terminals | 640017770 |

This document was generated on 02/01/2023

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION