

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0397000102](#)
Status: **Active**
Overview: Eurostyle Terminal Blocks
Description: 5.08mm Pitch, Eurostyle Fixed-Mount Push-Button Terminal Block, 45° Modular, 18A, 26-14 AWG, Green, 2 Circuits

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Terminal Blocks
Series	39700
Application	Wire-to-Board
Component Type	Push-Button
Overview	Eurostyle Terminal Blocks
Product Name	ESE, Eurostyle Fixed Mount
Taxonomy	Terminal Blocks and Barrier St
Type	Euro Block
UPC	78172542424

Physical

Circuits (Loaded)	2
Circuits (maximum)	2
Color - Resin	Green
Entry Angle	45° Angle
Lock to Mating Part	No
Material - Plating Termination	Tin
Material - Resin	Nylon
Number of Rows	1
Orientation	45° Angle
Panel Mount	Yes
Pitch - Mating Interface	5.08mm
Polarized to Mating Part	No
Stackable	No
Temperature Range - Operating	-40° to +105°C
Wire Size AWG	14, 16, 18, 20, 22, 24, 26

Electrical

Current - Maximum per Contact	18.0A
Voltage - Maximum	300V

Solder Process Data


Lead-free Process Capability	N/A
------------------------------	-----

Material Info

Engineering Number	M508-00-02-3
--------------------	--------------

Reference - Drawing Numbers

Sales Drawing	SD-39700-006-001
---------------	------------------

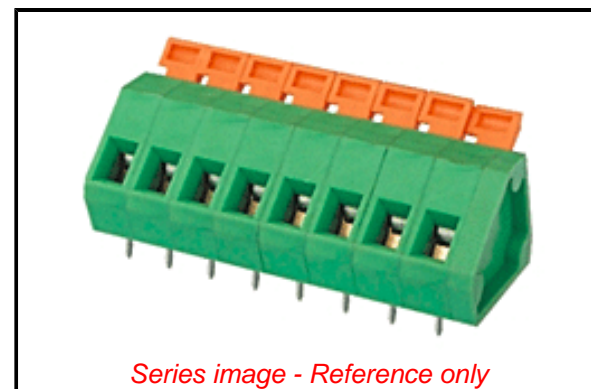

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2022)4187-DC (10
June 2022)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[39700 Series](#)