

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0984381004

Status:

Active

Description:

5.00mm Pitch NSCC/SICMA Female Wire-to-Board Housing, for 2.80mm Tab, with Bridges, Dual Row, 6 Circuits, Blue


Documents:

Drawing (PDF)

Application Specification AS-98438-001-001 (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	Crimp Housings
Series	98438
Application	Power, Wire-to-Board
Comments	For current designation please refer to FCI Sicma terminal specification for 2.80mm terminals.
Product Name	NSCC
Taxonomy	Connector Housings
UPC	822350104333
Physical	
Circuits (maximum)	6
Color - Resin	Black, Natural
Gender	Receptacle
Glow-Wire Capable	No
Lock to Mating Part	Yes
Material - Resin	Polyester
Net Weight	5.162/g
Number of Rows	2
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	5.00mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40° to +105°C
Solder Process Data	
Lead-freeProcess Capability	N/A
Material Info	
Reference - Drawing Numbers	
Application Specification	AS-98438-001-001
Sales Drawing	SD-98438-001-001

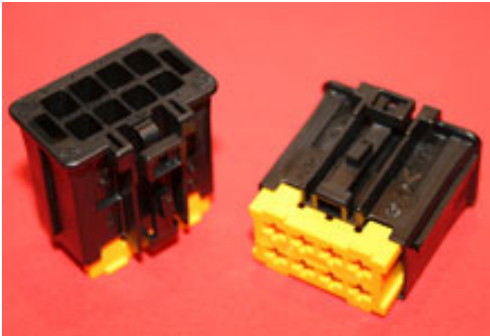

Series image - Reference only

EU ELV

Compliant

EU RoHS

Compliant

REACH SVHC

Not Contained Per - D(2022)4187-DC (10 June 2022)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China RoHS

Not Relevant

ELV

Compliant

RoHS Phthalates

Not Contained

Search Parts in this Series

98438 Series

Mates With

98898 UCC2 Terminals

Use With

98898

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION