


**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0466230501](#)  
**Status:** **Active**  
**Overview:** [Micro-Fit Connector System](#)  
**Description:** Micro-Fit BMI Receptacle Housing, Single Row, Panel Mount, 5 Circuits, Nylon, UL 94V-0

**Documents:**

<a href="#">3D Model (PDF)</a>	<a href="#">Application Specification 466250001-AS-000 (PDF)</a>
<a href="#">Drawing (PDF)</a>	<a href="#">Packaging Specification 466230000-PK-000 (PDF)</a>
<a href="#">3D Model</a>	<a href="#">Datasheet (PDF)</a>
<a href="#">Product Specification PS-44300-001-001 (PDF)</a>	<a href="#">RoHS Certificate of Compliance (PDF)</a>

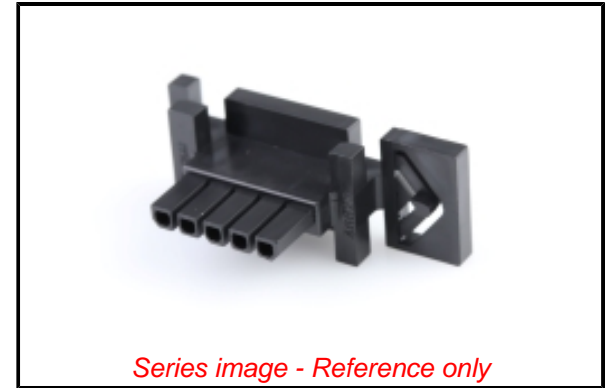

**Agency Certification**

CSA	LR19980
UL	E29179

**General**

Product Family	Crimp Housings
Series	<a href="#">46623</a>
Application	Power, Wire-to-Board, Wire-to-Wire
Overview	<a href="#">Micro-Fit Connector System</a>
Product Name	Micro-Fit BMI
Taxonomy	Connector Housings
UPC	887191458687

**Physical**

Circuits (maximum)	5
Color - Resin	Black
Flammability	94V-0
Gender	Receptacle
Glow-Wire Capable	No
Lock to Mating Part	No
Material - Resin	Nylon
Net Weight	1.478/g
Number of Rows	1
Packaging Type	Bag
Panel Mount	Yes
Pitch - Mating Interface	3.00mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40° to +105°C

**Solder Process Data**

Lead-freeProcess Capability	N/A
-----------------------------	-----

**Material Info**

**Reference - Drawing Numbers**

Application Specification	466250001-AS-000
Packaging Specification	466230000-PK-000
Product Specification	PS-44300-001-001
Sales Drawing	SD-46623-001-001

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per -  
D(2022)4187-DC (10  
June 2022)

**Halogen-Free**

**Status**

**Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

[46623](#) Series

**Mates With**

Micro-Fit BMI Plug Housing [46625](#) . Micro-Fit BMI Right Angle Header [46622](#)

**Use With**

Micro-Fit 3.0 Female Crimp Terminals [43030](#) , [45773](#) <br>Micro-Fit RMF Female Crimp Terminals [46235](#) <br>Micro-Fit 3.0 Pre-Crimped Leads [797580002](#) , [797580004](#) , [797580010](#) , [797580012](#) , [214760](#) , [214761](#)