

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0190580041

Status:

Active

Overview:

Solderless Terminals

Description:

Avikrimp Ring Tongue Terminal for 14-16 Heavy Duty AWG Wire

Documents:

3D Model

Product Specification PS-19902-011-001 (PDF)

3D Model (PDF)

Product Specification PS-19902-013-001 (PDF)

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification

CSA

LR18689

UL

E32244

General

Product Family

Ring and Spade Terminals

Series

19058

Comments

Heavy Duty

Crimp Quality Equipment

Yes

Overview

Solderless Terminals

Product Name

Avikrimp

Taxonomy

Ring and Spade Terminals

Type

Ring

UPC

800753059337

Physical

Barrel Type

Closed

Flammability

94V-2

Insulation

Nylon (PA)

Material - Plating Mating

Tin

Net Weight

2.567/g

Packaging Type

Bag

Plating min - Mating

2.540µm

Plating min - Termination

2.540µm

Stud Size

8 (M4)

Termination Interface: Style

Crimp or Compression

Wire Insulation Diameter

5.70mm max.

Wire Size AWG

14, 16

Wire Size mm²

1.30-2.00

Solder Process Data

Lead-freeProcess Capability

N/A

Material Info

Engineering Number

B-828-08HD


Reference - Drawing Numbers

Product Specification

PS-19902-011-001, PS-19902-013-001

Sales Drawing

190580016-000, 903-08

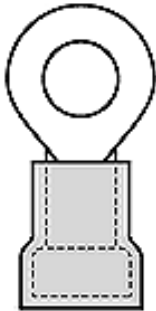

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -  
D(2022)4187-DC (10  
June 2022)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

19058 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION