

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0191980044

Status:

Active

Overview:

Solderless Terminals

Description:

Avikrimp Spade Tongue Terminal for 10-12 AWG Wire

Documents:

Drawing (PDF)

Product Specification PS-19902-011-001 (PDF)

Product Specification PS-19902-013-001 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification

CSA

LR18689

UL

E32244

General

Product Family

Ring and Spade Terminals

Series

19198

Crimp Quality Equipment

Yes

Overview

Solderless Terminals

Product Name

Avikrimp

Taxonomy

Ring and Spade Terminals

Type

Spade

UPC

800753046344

Physical

Barrel Type

Closed

Flammability

94V-0

Insulation

Nylon (PA)

Material - Plating Mating

Tin

Net Weight

2.388/g

Packaging Type

Bag

Plating min - Mating

2.540µm

Plating min - Termination

2.540µm

Stud Size

5-6 (M3-3.5)

Wire Insulation Diameter

5.70mm max.

Wire Size AWG

10, 12

Wire Size mm²

3.30-5.00

Material Info

Engineering Number

C-841-06


Reference - Drawing Numbers

Product Specification

PS-19902-011-001, PS-19902-013-001

Sales Drawing

191980044-000

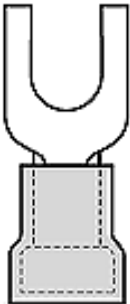

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

China RoHS

Compliant

REACH SVHC

Not Contained Per -

D(2022)4187-DC (10

June 2022)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

19198 Series

Application Tooling

FAQ

Tooling specifications and manuals are

found by selecting the products below.

Crimp Height Specifications are then

contained in the Application Tooling

Specification document.

Global	
Description	Product #
PremiumGrade	640010100
Hand Crimp Tool	
for Avikrimp and	
Insulkrimp Terminals	
and Splices,	
10-22 AWG and	
6.0-0.5mm² (Rings,	
Spades, Hooks,	
Block Spades and	
Flanged Spades)	
Crimp Head for the	640050100
AT-200 Pneumatic	
Hand Tool	

ServiceGrade Hand 640160036
Crimp Tool for Field
Repair only, for
production use our
PremiumGrade Tool

This document was generated on 02/02/2023

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION