

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

5601230800

Status:


Active

Overview:

DuraClik Connector System

Description:

DuraClik ISL Wire-to-Board Receptacle Housing, Single Row, White, 8 Circuits

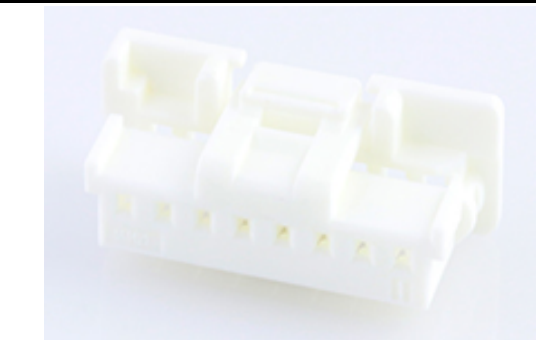

Series image - Reference only

Documents:	
3D Model	Application Specification AS-560123-001-001 (PDF)
3D Model (PDF)	Packaging Specification PK-560123-001-001 (PDF)
Drawing (PDF)	Datasheet (PDF)
Product Specification PS-560123-001-001 (PDF)	RoHS Certificate of Compliance (PDF)
Product Specification PS-560123-003-001 (PDF)	

Agency Certification	
UL	E29179
General	
Product Family	Crimp Housings
Series	560123
Application	Automotive, Signal, Wire-to-Board
Overview	DuraClik Connector System
Product Name	DuraClik
Taxonomy	Connector Housings
UPC	889056009553
Physical	
Circuits (maximum)	8
Color - Resin	White
Gender	Receptacle
Glow-Wire Capable	No
Keying to Mating Part	None
Lock to Mating Part	Yes
Material - Resin	PBT
Net Weight	0.455/g
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.00mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40° to +130°C
Solder Process Data	
Lead-freeProcess Capability	N/A
Material Info	
Reference - Drawing Numbers	
Application Specification	AS-560123-001-001
Packaging Specification	PK-560123-001-001
Product Specification	PS-560123-001-001, PS-560123-003-001
Sales Drawing	SD-560123-005-001

EU ELV Compliant	
EU RoHS Compliant	China RoHS
REACH SVHC Not Contained Per - D(2022)4187-DC (10 June 2022)	
Halogen-Free Status Not Low-Halogen	
For more information, please visit Contact US	
China ROHS ELV	Green Image Compliant
RoHS Phthalates	Not Contained

Search Parts in this Series
560123 Series

Mates With
DuraClik Right-Angle Header [502352](#)

DuraClik Vertical Header [560020](#)

Use With
DuraClik ISL Terminal [560124](#)
DuraClik
ISL Retainer [5601250800](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION