

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **0190720073**
Status: **Active**
Overview: Solderless Terminals
Description: VibraKrimp Ring Tongue Terminal for 16 - 14 AWG Wire, Stud Size 10 (M5), Length 16.69mm

Documents:

[3D Model](#) [Product Specification PS-19902-011-001 \(PDF\)](#)
[3D Model \(PDF\)](#) [Product Specification PS-19902-013-001 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR18689
 UL E32244

General

Product Family Ring and Spade Terminals
 Series [19072](#)
 Crimp Quality Equipment Yes
 Overview [Solderless Terminals](#)
 Product Name VibraKrimp
 Taxonomy Ring and Spade Terminals
 Type Ring
 UPC 800753074316

Physical

Barrel Type Closed
 Insulation None
 Material - Plating Mating Tin
 Net Weight 0.889g
 Packaging Type Bag
 Plating min - Mating 2.540µm
 Plating min - Termination 2.540µm
 Stud Size 10 (M5)
 Wire Size AWG 14, 16

Solder Process Data


Lead-freeProcess Capability N/A

Material Info

Engineering Number BB-437-10

Reference - Drawing Numbers

Product Specification PS-19902-011-001, PS-19902-013-001
 Sales Drawing 190720046-000

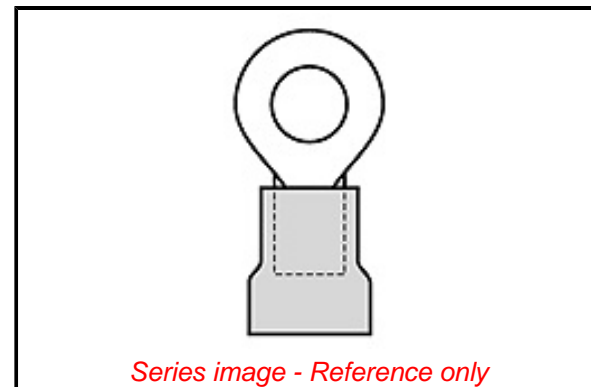

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
 D(2022)4187-DC (10
 June 2022)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[19072 Series](#)

Application Tooling | [FAQ](#)

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description	Product #
Crimp Hand Tool	640016800
Crimp Head for the AT-200 Pneumatic Hand Tool	640056800