

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** **0190700065**  
**Status:** **Active**  
**Overview:** Solderless Terminals  
**Description:** InsulKrimp Ring Tongue Terminal for 14-16 AWG Wire

**Documents:**

<a href="#">3D Model</a>	<a href="#">Product Specification PS-19902-011-001 (PDF)</a>
<a href="#">3D Model (PDF)</a>	<a href="#">Product Specification PS-19902-013-001 (PDF)</a>
<a href="#">Drawing (PDF)</a>	<a href="#">RoHS Certificate of Compliance (PDF)</a>
<a href="#">Product Specification PS-19902-009-001 (PDF)</a>	

**Agency Certification**

CSA	LR18689
UL	E32244

**General**

Product Family	Ring and Spade Terminals
Series	<u>19070</u>
Crimp Quality Equipment	Yes
Overview	<u>Solderless Terminals</u>
Product Name	InsulKrimp
Taxonomy	Ring and Spade Terminals
Type	Ring
UPC	800753069183

**Physical**


Barrel Type	Closed
Color - Resin	Natural
Flammability	94V-0
Insulation	PVC
Material - Plating Mating	Tin
Net Weight	0.746/g
Packaging Type	Bag
Plating min - Mating	4.064µm
Plating min - Termination	4.064µm
Stud Size	1-2 (M2)
Wire Insulation Diameter	4.40mm max.
Wire Size AWG	14, 16
Wire Size mm <sup>2</sup>	1.30-2.00

**Material Info**

Engineering Number	BB-223-02X
--------------------	------------

**Reference - Drawing Numbers**

Product Specification	PS-19902-009-001, PS-19902-011-001, PS-19902-013-001
Sales Drawing	SD-19070-008-001

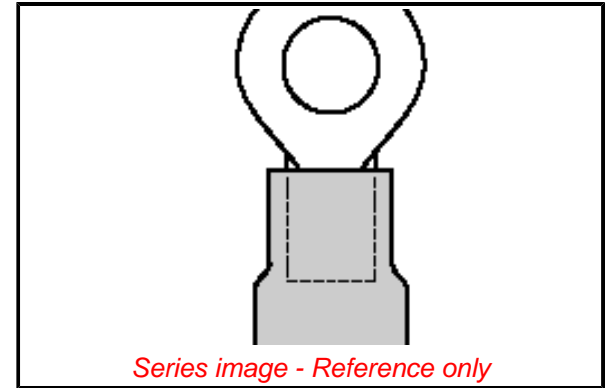

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per -  
D(2022)4187-DC (10  
June 2022)

**Halogen-Free**

**Status**

**Not Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

19070 Series

**Application Tooling | FAQ**

*Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.*

**Global**

**Description**

**Product #**

PremiumGrade	<u>640010100</u>
--------------	------------------

Hand Crimp Tool for Avikrimp and InsulKrimp Terminals and Splices, 10-22 AWG and 6.0-0.5mm<sup>2</sup> (Rings, Spades, Hooks, Block Spades and Flanged Spades)

PremiumGrade	<u>640010300</u>
--------------	------------------

Hand Crimp Tool for InsulKrimp Terminals and Splices, 10-22

AWG (Rings,  
Spades, Hooks,  
Block Spades and  
Flanged Spades)  
Crimp Head for the 640050100  
AT-200 Pneumatic  
Hand Tool  
Crimp Head for the 640050300  
AT-200 Pneumatic  
Hand Tool  
ServiceGrade Hand 640160036  
Crimp Tool for Field  
Repair only, for  
production use our  
PremiumGrade Tool

This document was generated on 02/02/2023

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**