

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0194300001](#)  
**Status:** **Active**  
**Overview:** [Splices](#)  
**Description:** See and Splice 2 Circuit Push-in Wire Connector for 12-22 AWG Wire

**Documents:**

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**Agency Certification**

UL E32244

**General**

Product Family Splices  
 Series [19430](#)  
 Comments Red Insert, 1000V max. for lighting/sign fixtures  
 Crimp Quality Equipment Yes  
 Overview [Splices](#)  
 Product Name See and Splice  
 Taxonomy Splices  
 UPC 822348218882

**Physical**

Barrel Type Closed  
 Color - Resin Red  
 Flammability 94V-2  
 Insulation None  
 Material - Metal Brass  
 Material - Plating Mating N/A  
 Net Weight 1.736/g  
 Packaging Type Bag  
 Temperature Range - Operating -30° to +105°C  
 Wire Insulation Diameter 3.30mm is the nominal O.D.  
 Wire Size AWG 12, 14, 16, 18, 20, 22

**Electrical**


Voltage - Maximum 600V

**Material Info**

Engineering Number PC2-RED

**Reference - Drawing Numbers**

Sales Drawing SD-19430-001-001

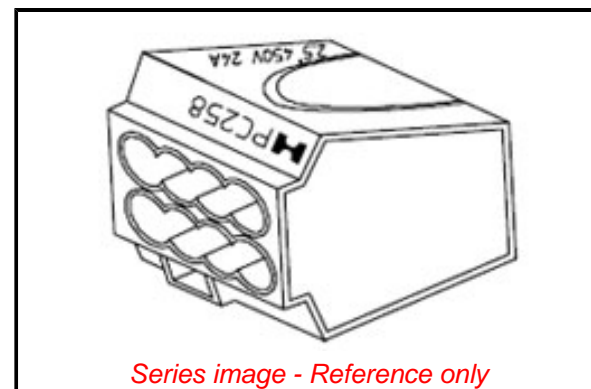

*Series image - Reference only*

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per  
 -ED/88/2018 (15  
 January 2019)

**Halogen-Free**

**Status**

**Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

[19430 Series](#)