

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0022552341

Status:


Active

Overview:

SL Modular Connectors

Description:

2.54mm Pitch SL Crimp Housing, Dual Row, Version A, Non-polarized, 34 Circuits, Black

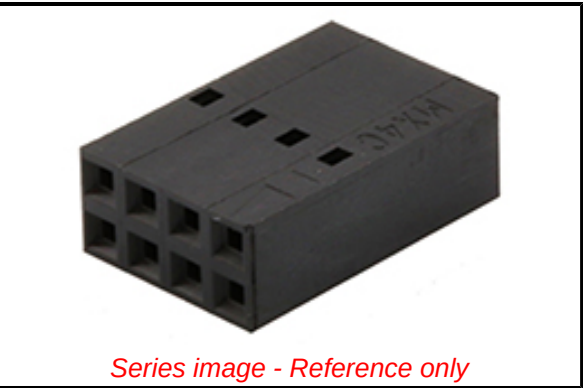

Series image - Reference only

Documents:	
3D Model	Product Specification PS-70400-001 (PDF)
Drawing (PDF)	Packaging Specification PK-70450-100-001 (PDF)
3D Model (PDF)	Test Summary TS-70058-001-001 (PDF)
Product Specification PS-70058-001 (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification		
CSA	LR19980	
UL	E29179	
General		
Product Family	Crimp Housings	
Series	70450	
Application	Signal, Wire-to-Board	
Comments	Version A	
Overview	SL Modular Connectors	
Product Name	SL	
Taxonomy	Connector Housings	
UPC	800753588790	
Physical		
Breakaway	No	
Circuits (maximum)	34	
Color - Resin	Black	
Flammability	94V-0	
Gender	Receptacle	
Glow-Wire Capable	No	
Material - Resin	Polyester	
Net Weight	2.890/g	
Number of Rows	2	
Packaging Type	Bag	
Panel Mount	No	
Pitch - Mating Interface	2.54mm	
Stackable	Yes	
Temperature Range - Operating	-40° to +105°C	
Solder Process Data		
Lead-freeProcess Capability	N/A	
Material Info		
Engineering Number	70450-0016	
Reference - Drawing Numbers		
Packaging Specification	PK-70450-100-001	
Product Specification	PS-70058-001, PS-70400-001	
Sales Drawing	SD-70450-0001-0026-001	
Test Summary	TS-70058-001-001	

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

70450 Series

Mates With

C-Grid Right-Angle Header [70229](#) , [70247](#) .

C-Grid Vertical Breakaway Header [70280](#) .

C-Grid Vertical Header [70246](#)

Use With

70058 , 71851

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION