

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

2125141012

Status:


Active

Overview:

Mini-Fit Family Power Connectors

Description:

Mini-Fit Max Receptacle Housing, Dual Row, UL 94V-0, 12 Circuits, Glow-Wire Capable, Black

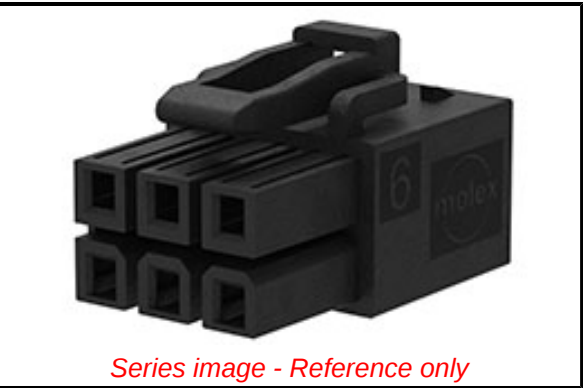

Documents:	
3D Model	Packaging Specification 2125140001-PK-000 (PDF)
3D Model (PDF)	Test Summary 2125150000-TS-000 (PDF)
Drawing (PDF)	Datasheet (PDF)
Product Specification 2125150000-PS-000 (PDF)	RoHS Certificate of Compliance (PDF)

General	
Product Family	Crimp Housings
Series	212514
Application	Power, Wire-to-Board, Wire-to-Wire
Overview	Mini-Fit Family Power Connectors
Product Name	Mini-Fit Max
Taxonomy	Connector Housings
UPC	193264598298
Physical	
Circuits (maximum)	12
Color - Resin	Black
Gender	Receptacle
Glow-Wire Capable	Yes
Keying to Mating Part	None
Lock to Mating Part	Yes
Material - Resin	Nylon
Net Weight	2.720/g
Number of Rows	2
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	4.20mm
Pitch - Termination Interface	4.20mm
Polarized to Mating Part	Yes
Temperature Range - Operating	-40° to +105°C

Material Info	
Reference - Drawing Numbers	
Packaging Specification	2125140001-PK-000
Product Specification	2125150000-PS-000
Sales Drawing	2125140001-SD-000
Test Summary	2125150000-TS-000

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2022)4187-DC (10 June 2022)	
Halogen-Free	
Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

212514 Series

Mates With

Mini-Fit Max Header 212520

Use With

Mini-Fit Max Crimp Terminal 212515 . Mini-Fit Max TPA 2125161006

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION