

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0701070050

Status:


Active

Overview:

SL Modular Connectors

Description:

SL Wire-to-Wire Panel Mount Crimp Housing, Single Row, Version B, with Mounting Ears, 16 Circuits, Black

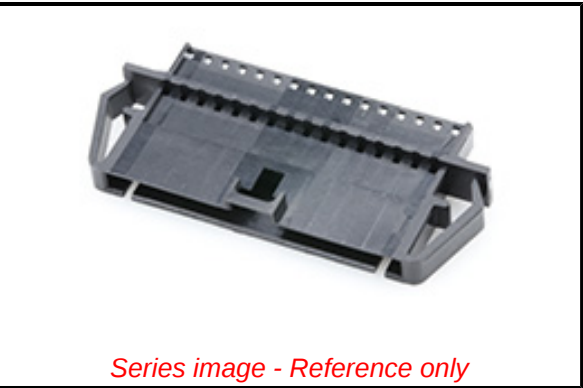

Series image - Reference only

Documents:	
3D Model (PDF)	Product Specification PS-70400-001 (PDF)
3D Model	Packaging Specification PK-70107-100-001 (PDF)
Drawing (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR19980
UL	E29179
General	
Product Family	Crimp Housings
Series	70107
Application	Signal, Wire-to-Wire
Comments	Version B with Mounting Ears
Overview	SL Modular Connectors
Product Name	SL
Taxonomy	Connector Housings
UPC	800755031188
Physical	
Circuits (maximum)	16
Color - Resin	Black
Flammability	94V-0
Gender	Plug
Glow-Wire Capable	No
Lock to Mating Part	None
Material - Resin	Polyester
Net Weight	3.397/g
Number of Rows	1
Packaging Type	Bag
Panel Mount	Yes
Pitch - Mating Interface	2.54mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40° to +105°C
Material Info	
Reference - Drawing Numbers	
Packaging Specification	PK-70107-100-001
Product Specification	PS-70400-001
Sales Drawing	SD-70107-0036-0059-001, SD-70107-0036-0059-002, SD-70107-0036-0059-003

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2022)4187-DC (10 June 2022)	
Halogen-Free	
Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

70107 Series

Mates With

SL Crimp Housing Versions A, G and D Only [70066](#) (Version C and H will not mate to the 70107 housing series) . SL Insulation Displacement Connector Assembly, Version G Housing [70400](#) . SL Single Row Receptacle, Version G [70430](#)

Use With

[70021](#) SL Crimp Terminal

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION